


# nVent CADDY Speed Link SLK with Threaded Stud End



## CERTIFICATIONS

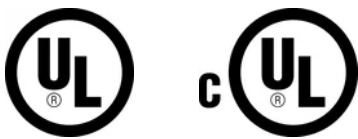

## FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Polypropylene;Zinc Alloy
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2


Catalog Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)	Width (W)
SLK15L2SE250	1.5 mm	6.6'	1/4"	1"	2.15"	3/4"

CatalogNumber	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)	Width (W)
SLK15L3SE250	1.5 mm	9.9'	1/4"	1"	2.15"	3/4"
SLK2L3SE375	2 mm	9.9'	3/8"	1 3/4"	2.15"	3/4"
SLK2L5SE375	2 mm	16.4'	3/8"	1 3/4"	2.15"	3/4"
SLK3L3SE375	3 mm	9.9'	3/8"	1 3/4"	2 1/2"	0.9"

Table 2/2

Catalog Number	Thickness (T)	Angle (a)	Static Load (F)	Certifications
SLK15L2SE250	1/2"	90 ° Max	44lbf	UL, cUL
SLK15L3SE250	1/2"	90 ° Max	44lbf	UL, cUL
SLK2L3SE375	1/2"	90 ° Max	100lbf	cUL, UL
SLK2L5SE375	1/2"	90 ° Max	100lbf	UL, cUL
SLK3L3SE375	0.6"	90 ° Max	200lbf	

## DIAGRAMS

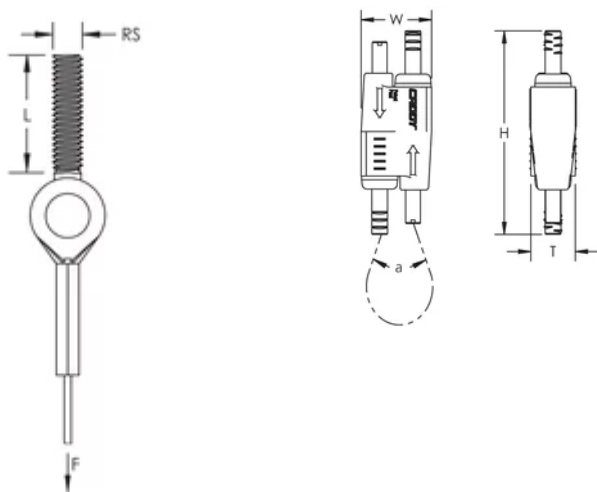

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

