


nVent CADDY Speed Link SLK with Toggle



CERTIFICATIONS

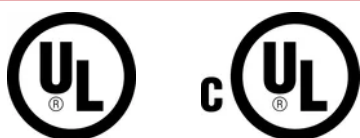

FEATURES

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

SPECIFICATIONS

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS


Table 1/1

Catalog Number	Wire Rope Length	A	B	Static Load (F)
SLK15L10T	32.8'	1.54"	0.2"	44lbf

Catalog Number	Wire Rope Length	A	B	Static Load (F)
SLK15L1T	3.3'	1.54"	0.2"	44lbf
SLK15L1TR2	3.3'	1.54"	0.2"	44lbf
SLK15L2T	6.6'	1.54"	0.2"	44lbf
SLK15L2TR2	6.6'	1.54"	0.2"	44lbf
SLK15L3T	9.9'	1.54"	0.2"	44lbf
SLK15L3TR2	9.9'	1.54"	0.2"	44lbf
SLK15L5T	16.4'	1.54"	0.2"	44lbf
SLK15L7T	22.9'	1.54"	0.2"	44lbf

Thickness (T): 1/2"
Width (W): 3/4"
Height (H): 2.15"
Angle (a): 90 ° Max

DIAGRAMS

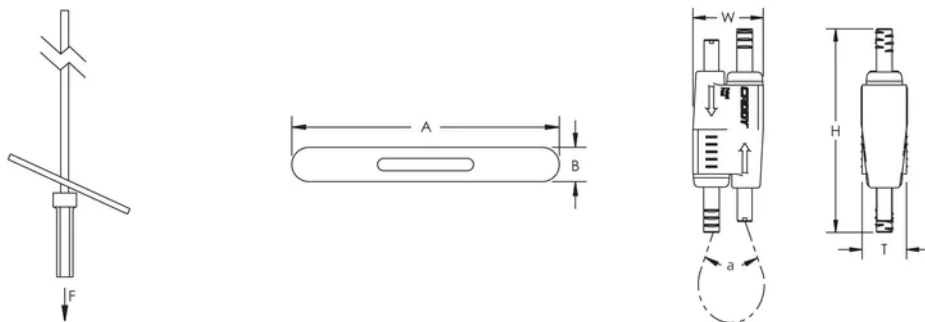

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

