


nVent CADDY Speed Link SLK with Y-Toggle



CERTIFICATIONS

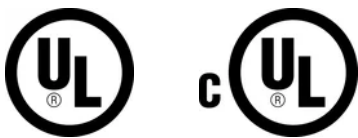

FEATURES

Complete system includes wire, locking device and two pre-assembled toggle end fittings

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS


Table 1/1

Catalog Number	Wire Rope Diameter	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B	Static Load (F)
SLK15Y300L3	1.5 mm	9.9'	11.8"	1.54"	0.2"	44lbf

CatalogNumber	Wire Rope Diameter	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B	Static Load (F)
SLK15Y300L3R 2	1.5 mm	9.9'	11.8"	1.54"	0.2"	44lbf
SLK15Y300L5	1.5 mm	16.4'	11.8"	1.54"	0.2"	44lbf
SLK15Y500L3	1.5 mm	9.9'	19.6"	1.54"	0.2"	44lbf
SLK15Y500L3R 2	1.5 mm	9.9'	19.6"	1.54"	0.2"	44lbf
SLK2Y300L2	2 mm	6.6'	11.8"	1.65"	0.31"	100lbf
SLK2Y300L3	2 mm	9.9'	11.8"	1.65"	0.31"	100lbf
SLK2Y300L3R2	2 mm	9.9'	11.8"	1.65"	0.31"	100lbf

Thickness (T): 1/2"
Width (W): 3/4"
Height (H): 2.15"
Angle (a): 90 ° Max

DIAGRAMS

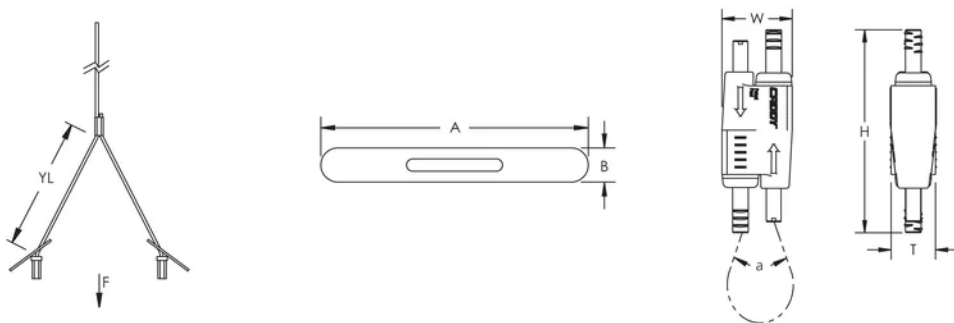

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

