


nVent CADDY Speed Link Y-Hook with Eyelet Extension

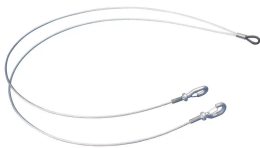

CERTIFICATIONS



FEATURES

Double hook offers easy attachment to basket tray, cable tray or lighting

Convenient design allows one hook to be temporarily detached for maintenance or to add cables to the tray

Y-design provides improved stability

Spring latch helps provide secure connection

SPECIFICATIONS

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel

Table 1/1


Catalog Number	Wire Rope "Y" Length (YL)	A	B	C	Static Load (F)	Certifications
----------------	---------------------------	---	---	---	-----------------	----------------

SLD2YH500	19.6"	2.3"	0.9"	1/4"	100lbf	UL, cUL, ITB
SLD2YH800	31.4"	2.3"	0.9"	1/4"	100lbf	UL, cUL

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

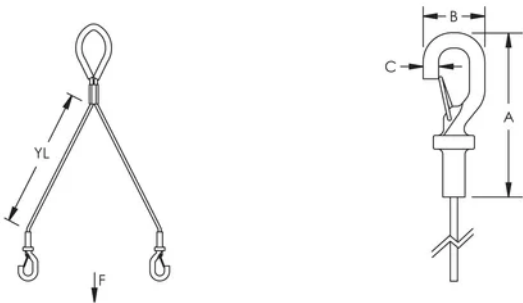

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

