

nVent CADDY Speed Link Y-Toggle with Eyelet Extension



CERTIFICATIONS



FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

SPECIFICATIONS

Static Load Safety Factor: 5:1
Finish: Electrogalvanized
Material: Steel

Table 1/1


Catalog Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load (F)	Certifications
SLD15Y200	1.5 mm	7.8"	1.54"	0.2"	44lbf	UL, cUL

CatalogNumber	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load (F)	Certifications
SLD15Y500	1.5 mm	19.6"	1.54"	0.2"	44lbf	UL, cUL, ITB
SLD15Y800	1.5 mm	31.4"	1.54"	0.2"	44lbf	UL, cUL, ITB
SLD2Y500	2 mm	19.6"	1.65"	0.31"	100lbf	UL, ITB, cUL

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

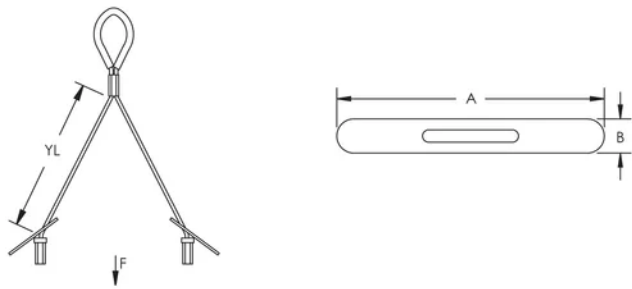

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

