

# nVent CADDY Superfix 454 Standard Duty



## FEATURES

Recommended for the suspension of stationary non-insulated pipe lines

Easy-to-close clamp for steel pipe and copper tube

Unique hinged design eliminates the need to disassemble the clamp prior to installation

Clamp can be closed with one hand, without ever turning a screw

All-steel design of the closing mechanism retains strength even when exposed to heat

Comes with a welded 3/8" cap nut, allowing easy attachment to threaded rod

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;EPDM-SBR Rubber
<b>Temperature:</b>	-58 to 230 °F

Table 1/2

Catalog Number	Outer Diameter (OD)	Pipe Size	Copper Tube Size	Rod Size (RS)	B
454001	0.470" - 0.55"	1/4"	3/8"	3/8"	0.90625"

Catalog Number	Outer Diameter (OD)	Pipe Size	Copper Tube Size	Rod Size (RS)	B
454002	0.590" - 3/4"	3/8"	1/2"	3/8"	0.90625"
454003	3/4" - 0.83"		5/8"	3/8"	0.90625"
454004	0.830" - 0.91"	1/2"	3/4"	3/8"	0.90625"
454005	1.020" - 1.1"	3/4"	1"	3/8"	0.90625"
454006	1.260" - 1.38"	1"	1 1/4"	3/8"	0.90625"
454007	1.570" - 1.69"	1 1/4" Min	1 1/2"	3/8"	0.90625"
454008	1.890" - 2.05"	1 1/2"		3/8"	0.90625"
454009	2.120" - 2.28"		2"	3/8"	15/16"
454010	2.240" - 2.4"	2" Min		3/8"	0.90625"
454011	2.480" - 2.64"		2 1/2"	3/8"	0.90625"
454012	2.740" - 2.88"	2 1/2"		3/8"	15/16"
454013	2.910" - 3.16"		3"	3/8"	15/16"
454014	3.270" - 3.58"	3"		3/8"	15/16"
454015	3.620" - 3.94"		3 1/2"	3/8"	0.90625"
454016	3.980" - 4.17"	3 1/2"	4"	3/8"	1 1/8"
454017	4 1/4" - 4.49"	4"		3/8"	1 1/8"

Table 2/2

Catalog Number	Static Load (F)
454001	180lbf


Catalog Number	Static Load (F)
454002	180lbf
454003	180lbf
454004	180lbf
454005	180lbf
454006	180lbf
454007	180lbf
454008	180lbf
454009	180lbf
454010	180lbf
454011	300lbf
454012	300lbf
454013	300lbf
454014	300lbf
454015	300lbf
454016	300lbf
454017	300lbf

## ADDITIONAL PRODUCT DETAILS

---

Lining is EPDM rubber.

DIAGRAMS

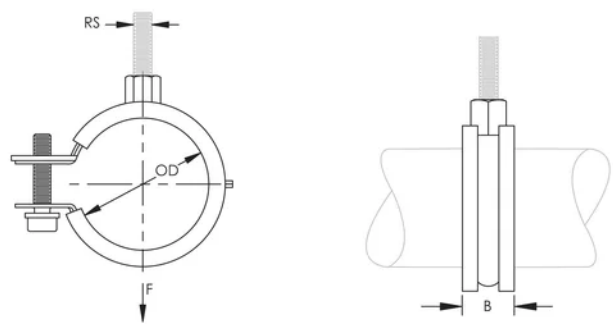

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

