


nVent CADDY UUM Bracket on Stud Assembly

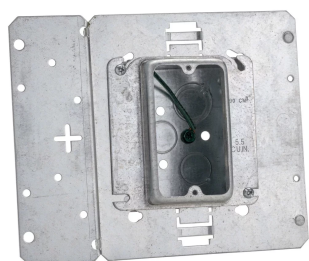

FEATURES

Rigid design, no far side support required when mounted on left or right of stud

Works with both standard and adjustable single and double gang mud rings

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Knockout Sizes	Box Depth	Box Size	Box Volume
UM4DV1	Steel	Pregalvanized	(4) 1/2", 3/4", (8) 1/2"	2.12"	4"	30.3in ³

Table 2/2

Catalog Number	Drywall Thickness	Gang	Ground Wire Included	Mud Ring Type
UM4DV1	3/4" - 1 1/2"	1	Yes	Adjustable

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

