



# Open Back Box

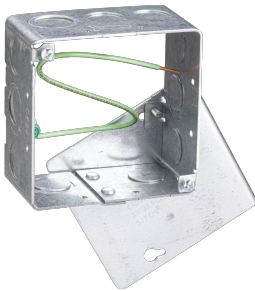

The nVent CADDY Open Back Box provides fast and easy access when installing electrical wiring, conduit connectors, and data cables. With a versatile removable back plate, contractors gain the unique option of opening the entire area of the box. Make wiring connections and knockout installation simpler and more efficient. Ideal for prefab installations where devices, fittings, and cables are installed to quickly and easily complete make-up wiring connections, without the need to drop or work through the mud ring.

The nVent CADDY Open Back Box series is offered in both 4" and 4 11/16" sizes and power and data versions of the 4 11/16" box with knockout sized accordingly. To further increase overall productivity, savings, and job site safety, pair with our full line of between-stud and on-stud nVent CADDY In-Wall supports. This can also be ordered as part of our Standard Prefab Assemblies and any nVent CADDY Custom Pre-Assembled Solutions built to your specification.

## CERTIFICATIONS

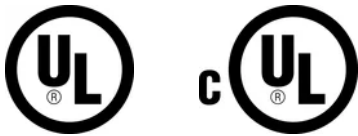

## FEATURES

Detachable back plate for quick access to wiring without removing mud ring

Open-back methodology provides versatility and installation efficiency

Rigid support prevents kickback into stud wall

Multiple knockouts for installing raceways

4 11/16" back plate has two 3/4" and two 1" knock outs

Application-specific sizing options available

Front of box designed for U.S. plaster ring and cover screw locations

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2

Catalog Number	Box Size	Box Depth	Knockout Sizes	Box Type	Height (H)	Length (L)
OBB4	4"	2.19"	(4) 1/2", 3/4", (7) 1/2"	Open	4.12"	4"
OBB41	4 11/16"	2 1/2"	(11) 1/2", 3/4"	Open	4.6875"	4.6875"
OBB41D	4 11/16"	2 1/2"	(8) 1", 1 1/4"	Open	4.6875"	4.6875"


Table 2/2

Catalog Number	Width (W)
OBB4	2.35"
OBB41	2.5"
OBB41D	2.5"

## ADDITIONAL PRODUCT DETAILS

Use with products designed for U.S. box screw configurations.

## DIAGRAMS

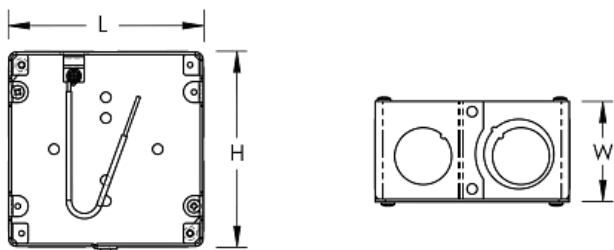

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

