

RA Right Angle Pipe and Conduit Clamp



FEATURES

Fix pipe or conduit perpendicular to a beam

SPECIFICATIONS


Material: Cast Iron

Finish: Hot-Dip Galvanized

Table 1/1

Catalog Number	Rigid Conduit Size	Pipe Size	Flange Thickness (FT)	Static Load (F)
RA0050HD	1/2"	1/2"	3/4" Max	250lb
RA0075HD	3/4"	3/4"	3/4" Max	300lb
RA0100HD	1"	1"	3/4" Max	400lb
RA0125HD	1 1/4"	1 1/4" Min	3/4" Max	400lb
RA0150HD	1 1/2"	1 1/2"	3/4" Max	500lb
RA0200HD	2"	2" Min	3/4" Max	600lb

DIAGRAMS

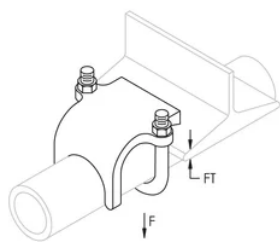

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

