

RIGD Single Piece Strut Clamp for Pipe/Rigid Conduit



CERTIFICATIONS



FEATURES

One piece break apart strut clamp (1/2" thru 4" pipe size)

Includes thread impression and captured screw (1/2" thru 4" pipe size)

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Pipe Size	Outer Diameter (OD)	Width (W)	Thickness (T)
RIGD0050EG	Steel	Electrogalvanized	1/2"	0.84"	1 1/4"	14ga
RIGD0050S4	Stainless Steel 304 (EN 1.4301)		1/2"	0.84"	1 1/4"	14ga

CatalogNumber	Material	Finish	Pipe Size	Outer Diameter (OD)	Width (W)	Thickness (T)
RIGD0075EG	Steel	Electrogalvanized	3/4"	1.05"	1 1/4"	14ga
RIGD0075S4	Stainless Steel 304 (EN 1.4301)		3/4"	1.05"	1 1/4"	14ga
RIGD0100EG	Steel	Electrogalvanized	1"	1.31"	1 1/4"	14ga
RIGD0100S4	Stainless Steel 304 (EN 1.4301)		1"	1.31"	1 1/4"	14ga
RIGD0125EG	Steel	Electrogalvanized	1 1/4" Min	1.66"	1 1/4"	14ga
RIGD0125S4	Stainless Steel 304 (EN 1.4301)		1 1/4" Min	1.66"	1 1/4"	14ga
RIGD0150EG	Steel	Electrogalvanized	1 1/2"	1.9"	1 1/4"	12ga
RIGD0150S4	Stainless Steel 304 (EN 1.4301)		1 1/2"	1.9"	1 1/4"	12ga
RIGD0200EG	Steel	Electrogalvanized	2" Min	2 3/8"	1 1/4"	12ga
RIGD0200S4	Stainless Steel 304 (EN 1.4301)		2" Min	2 3/8"	1 1/4"	12ga
RIGD0250EG	Steel	Electrogalvanized	2 1/2"	2 7/8"	1 1/4"	12ga
RIGD0250S4	Stainless Steel 304 (EN 1.4301)		2 1/2"	2 7/8"	1 1/4"	12ga
RIGD0300EG	Steel	Electrogalvanized	3"	3 1/2"	1 1/4"	12ga
RIGD0300S4	Stainless Steel 304 (EN 1.4301)		3"	3 1/2"	1 1/4"	12ga
RIGD0350EG	Steel	Electrogalvanized	3 1/2"	4"	1 1/4"	11ga
RIGD0400EG	Steel	Electrogalvanized	4"	4 1/2"	1 1/4"	11ga


CatalogNumber	Material	Finish	Pipe Size	Outer Diameter (OD)	Width (W)	Thickness (T)
RIGD0400S4	Stainless Steel 304 (EN 1.4301)		4"	4 1/2"	1 1/4"	11ga

Table 2/2

Catalog Number	Static Load (F)
RIGD0050EG	400lbf
RIGD0050S4	400lbf
RIGD0075EG	600lbf
RIGD0075S4	600lbf
RIGD0100EG	600lbf
RIGD0100S4	600lbf
RIGD0125EG	600lbf
RIGD0125S4	600lbf
RIGD0150EG	800lbf
RIGD0150S4	800lbf
RIGD0200EG	800lbf
RIGD0200S4	800lbf
RIGD0250EG	800lbf
RIGD0250S4	800lbf
RIGD0300EG	800lbf

Catalog Number	Static Load (F)
RIGD0300S4	800lbf
RIGD0350EG	1000lbf
RIGD0400EG	1000lbf
RIGD0400S4	1000lbf

DIAGRAMS

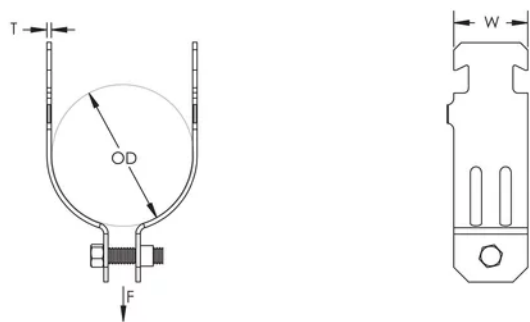

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

