

SK Single Piece Strut Clamp for Conduit



CERTIFICATIONS



FEATURES

One piece break apart strut clamp for EMT and Rigid conduit

Includes thread impression and captured screw

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	EMT Conduit Size	Rigid Conduit/Pipe Size	Outer Diameter (OD)	Width (W)
SK85I	Steel	Electrogalvanized	1/2"	1/2"	0.710" - 0.84"	1 1/4"
SK8ALA	Aluminum		1/2"	1/2"	0.710" - 0.84"	1 1/4"
SK125I	Steel	Electrogalvanized	3/4"	3/4"	0.920" - 1.05"	1 1/4"
SK12ALA	Aluminum		3/4"	3/4"	0.920" - 1.05"	1 1/4"


CatalogNumber	Material	Finish	EMT Conduit Size	Rigid Conduit/Pipe Size	Outer Diameter (OD)	Width (W)
SK165I	Steel	Electrogalvanized	1"	1"	1.160" - 1.32"	1 1/4"
SK16ALA	Aluminum		1"	1"	1.160" - 1.32"	1 1/4"
SK205I	Steel	Electrogalvanized	1 1/4"	1 1/4"	1.510" - 1.66"	1 1/4"
SK20ALA	Aluminum		1 1/4"	1 1/4"	1.510" - 1.66"	1 1/4"
SK245I	Steel	Electrogalvanized	1 1/2"	1 1/2"	1.740" - 1.9"	1 1/4"
SK24ALA	Aluminum		1 1/2"	1 1/2"	1.740" - 1.9"	1 1/4"
SK325I	Steel	Electrogalvanized	2"	2"	2.200" - 2.38"	1 1/4"
SK32ALA	Aluminum		2"	2"	2.200" - 2.38"	1 1/4"
SK405I	Steel	Electrogalvanized	2 1/2"	2 1/2"	2.88"	1 1/4"
SK485I	Steel	Electrogalvanized	3"	3"	3 1/2"	1 1/4"
SK565I	Steel	Electrogalvanized	3 1/2"	3 1/2"	4"	1 1/4"
SK645I	Steel	Electrogalvanized	4"	4"	4 1/2"	1 1/4"

Table 2/2

Catalog Number	Static Load (F)	Certifications
SK85I	200lb	cUL, UL
SK8ALA	150lb	
SK125I	200lb	UL, cUL
SK12ALA	150lb	

Catalog Number	Static Load (F)	Certifications
SK165I	200lb	cUL, UL
SK16ALA	150lb	
SK205I	200lb	UL, cUL
SK20ALA	150lb	
SK245I	200lb	cUL, UL
SK24ALA	150lb	
SK325I	200lb	UL, cUL
SK32ALA	150lb	
SK405I	350lb	cUL, UL
SK485I	350lb	UL, cUL
SK565I	350lb	cUL, UL
SK645I	350lb	UL, cUL

DIAGRAMS

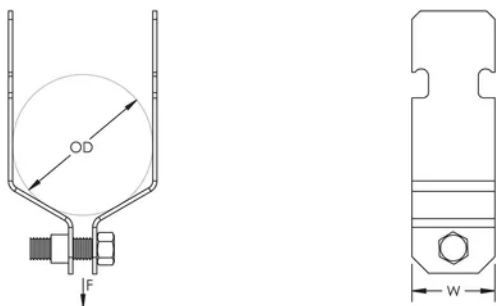

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

