

Strut Nut without Spring



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Static Load Safety Factor: 3:1


Table 1/1

Catalog Number	Material	Finish	Thickness (T)	Torque (TQ)
NUTM6S6	Stainless Steel 316 (EN 1.4401)		0.24"	8.85 ft·lbf
NUTM8EG	Steel	Electrogalvanized	0.24"	20.65 ft·lbf
NUTM6EG	Steel	Electrogalvanized	0.24"	8.85 ft·lbf
NUTM6HD	Steel	Hot-Dip Galvanized	0.24"	8.85 ft·lbf
NUTM8S6	Stainless Steel 316 (EN 1.4401)		0.24"	20.65 ft·lbf
NUTM8HD	Steel	Hot-Dip Galvanized	0.24"	20.65 ft·lbf
NUTM12S6	Stainless Steel 316 (EN 1.4401)		0.32"	40.57 ft·lbf

Catalog Number	Material	Finish	Thickness (T)	Torque (TQ)
NUTM12HD	Steel	Hot-Dip Galvanized	0.32"	40.57 ft·lbf
NUTM12EG	Steel	Electrogalvanized	0.32"	40.57 ft·lbf
NUTM10S6	Stainless Steel 316 (EN 1.4401)		0.32"	40.57 ft·lbf
NUTM10HD	Steel	Hot-Dip Galvanized	0.32"	40.57 ft·lbf
NUTM10EG	Steel	Electrogalvanized	0.32"	40.57 ft·lbf
NUTM16HD	Steel	Hot-Dip Galvanized	0.46"	92.2 ft·lbf
NUTM16EG	Steel	Electrogalvanized	0.46"	92.2 ft·lbf
NUTM12THD	Steel	Hot-Dip Galvanized	0.46"	47.94 ft·lbf

Pull-Out Strength			
Part Number	Channel Type	Channel Thickness	
		12 GA	14 GA
NUT0025xx	A, C	450 lb	450 lb
	D, E	450 lb	-
NUT0037xx	A, C	1,100 lb	1,000 lb
	D, E	1,100 lb	-
NUT0050xx	A	2,000 lb	1,400 lb
	D, E	1,500 lb	-
NUT0062xx	A	2,000 lb	1,400 lb
	D, E	1,500 lb	-
NUT0075xx	A	2,000 lb	1,400 lb
	D, E	1,500 lb	-

DIAGRAMS

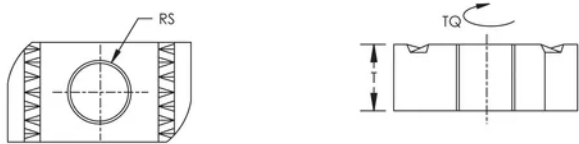

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

