

TDHT Trapezoidal Deck Hanger with Nut



FEATURES

Easy install

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Rod Size (RS)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Hole Size 3 (HS3)	D
TDHT4	1/4"	0.27"	0.55"	0.41"	2" Max
TDHT6	3/8"	0.27"	0.55"	0.41"	2" Max

Ceiling Thickness	Static Load F
.0248" - .0276"	130 lb
.0277" - .0315"	150 lb
.0316" - .0394"	180 lb
.0395" - .0472"	225 lb

DIAGRAMS

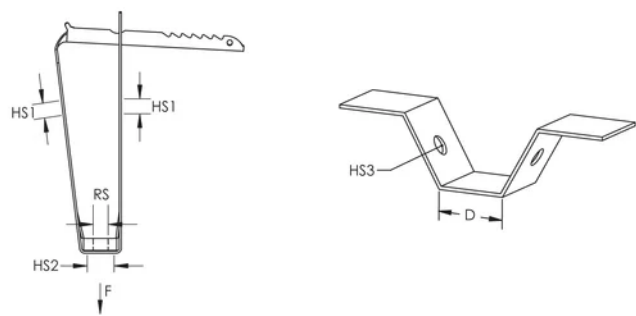

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

