

Telescoping Plumbing Bracket Clip, Horizontal



The nVent CADDY Telescoping Plumbing Bracket Clip horizontal orientation provides contractors a quick and easy way to install supply and drain lines within stud walls. This innovative tool-free design allows for faster installs and adjustments, as well as greater flexibility. When combined with the nVent CADDY Telescoping Plumbing Bracket this system delivers a complete solution that will save contractors time and money.

CERTIFICATIONS



FEATURES

Can be used for horizontal mounting in conjunction with the nVent CADDY Telescoping Plumbing Bracket Clip

Accommodates both ½ and ¾ inch Pex Tubing and Copper Pipe—reducing number of SKUs required

Quickly attaches and secures to the bracket without the use of tools or hardware

Due to the wraparound design, clips can be added before or after lines have been run

Innovative design allows for easy adjustment and repositioning of the clip anywhere along the span of the bracket—simply pinch tabs on the clip and slide in either direction

Horizontal mounting clip can also be attached directly to stud for use as a through-stud grommet (requires screw to secure to stud)

SPECIFICATIONS


Table 1/2

Catalog Number	Copper Tube Size	Height (H)	Length (L)	Material	Outer Diameter (OD)	PEX Tube Size
----------------	------------------	------------	------------	----------	---------------------	---------------

TPB75H	0.50" - 0.75"	2.96"	0.9"	High Density Polyethylene (HDPE)	0.625" - 0.875"	0.50" - 0.75"
--------	---------------	-------	------	----------------------------------	-----------------	---------------

Table 2/2		
Catalog Number	Pipe Size	Width (W)
TPB75H	0.5"	2.95"

DIAGRAMS

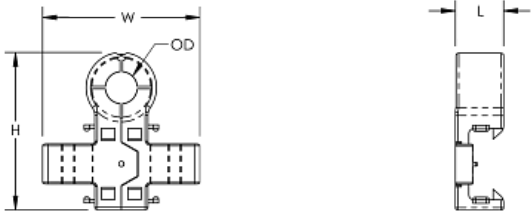

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

