


# WBT Performance Cable Tray Bar Splice

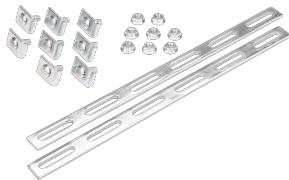

The nVent CADDY WBT Performance Cable Tray Bar Splice connects straight sections and fittings for your shaped tray needs.

## CERTIFICATIONS



## FEATURES

Available in multiple finishes to match your installation

Standard bar for splicing wire basket tray

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Color	Height	Width	Length	Slot Size	Unit Weight
WBTBSPLICE		0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb
WBTBSPLICEB A	Black	0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb

CatalogNumber	Color	Height	Width	Length	Slot Size	Unit Weight
WBTBSPLICEKIT		0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb
WBTBSPLICEKITBA	Black	0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb
WBTBSPLICEKITWH	White	0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb
WBTBSPLICEWH	White	0.179"	0.688"	12"	0.25" x 1.44"	0.28 lb

Table 2/2

Catalog Number	Certifications
WBTBSPLICE	
WBTBSPLICEBA	
WBTBSPLICEKIT	UL
WBTBSPLICEKITBA	UL
WBTBSPLICEKITWH	
WBTBSPLICEWH	

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

