


WBT Performance Cable Tray PreForm Elbow 90°

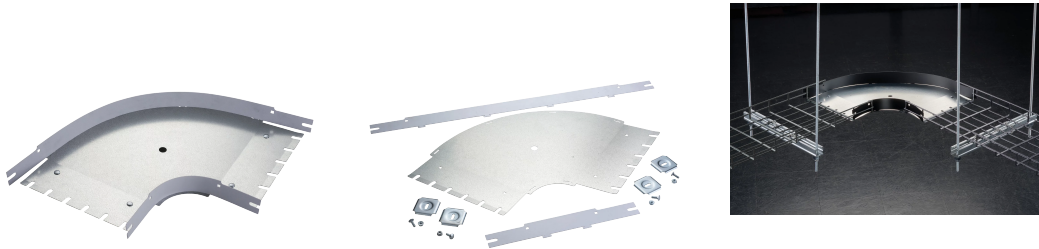

The nVent CADDY WBT Performance Cable Tray PreForm Elbow features a radius junction with a pre-galvanized base and interlocking polymer side walls that save time with consistent installation. The PreForm Elbow 90° is a revolutionary solution for seamless intersections ensuring clean engineering precision and effortless attachment without cutting or configuring. Due to its unique design, this offering provides up to 60% reduction in labor and time compared to traditional methods while maintaining flexibility and cost-effectiveness in tray pathway retrofits.

CERTIFICATIONS



FEATURES

Labor savings up to 60%

Maintains UL classification throughout installation

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2

Catalog Number	Color	Height	Width	Length	Angle	Unit Weight
----------------	-------	--------	-------	--------	-------	-------------

WBTR902X4		2"	12 1/2"	12 1/2"	90 °	0.206 lb
WBTR902X4BA	Black	2"	12 1/2"	12 1/2"	90 °	0.206 lb
WBTR902X4WH	White	2"	12 1/2"	12 1/2"	90 °	0.206 lb
WBTR902X6		2"	14.4"	14.4"	90 °	0.411 lb
WBTR902X6BA	Black	2"	14.4"	14.4"	90 °	0.411 lb
WBTR902X6WH	White	2"	14.4"	14.4"	90 °	0.411 lb
WBTR902X8		2"	16.4"	16.4"	90 °	0.411 lb
WBTR902X8BA	Black	2"	16.4"	16.4"	90 °	0.411 lb
WBTR902X8WH	White	2"	16.4"	16.4"	90 °	0.411 lb
WBTR902X12		2"	20.3"	20.3"	90 °	0.823 lb
WBTR902X12BA	Black	2"	20.3"	20.3"	90 °	0.823 lb
WBTR902X12WH	White	2"	20.3"	20.3"	90 °	0.823 lb
WBTR902X16		2"	24.3"	24.3"	90 °	1.235 lb
WBTR902X16WH	White	2"	24.3"	24.3"	90 °	1.235 lb
WBTR902X18		2"	26.21"	26.21"	90 °	1.44 lb
WBTR902X18BA	Black	2"	26.21"	26.21"	90 °	1.44 lb
WBTR902X18WH	White	2"	26.21"	26.21"	90 °	1.44 lb

WBTR902X20B A	Black	2"	28.2"	28.2"	90 °	1.852 lb
WBTR902X24		2"	32.2"	32.2"	90 °	2.263 lb
WBTR902X24B A	Black	2"	32.2"	32.2"	90 °	2.263 lb
WBTR902X24W H	White	2"	32.2"	32.2"	90 °	2.263 lb

Table 2/2

Catalog Number	Certifications
WBTR902X4	cUL, UL
WBTR902X4BA	
WBTR902X4WH	
WBTR902X6	UL, cUL
WBTR902X6BA	
WBTR902X6WH	
WBTR902X8	cUL, UL
WBTR902X8BA	
WBTR902X8WH	
WBTR902X12	UL, cUL
WBTR902X12BA	
WBTR902X12WH	
WBTR902X16	cUL, UL

Catalog Number	Certifications
WBTR902X16WH	
WBTR902X18	UL, cUL
WBTR902X18BA	
WBTR902X18WH	
WBTR902X20BA	
WBTR902X24	UL, cUL
WBTR902X24BA	
WBTR902X24WH	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

