


# WBT Performance Cable Tray PreForm Intersection

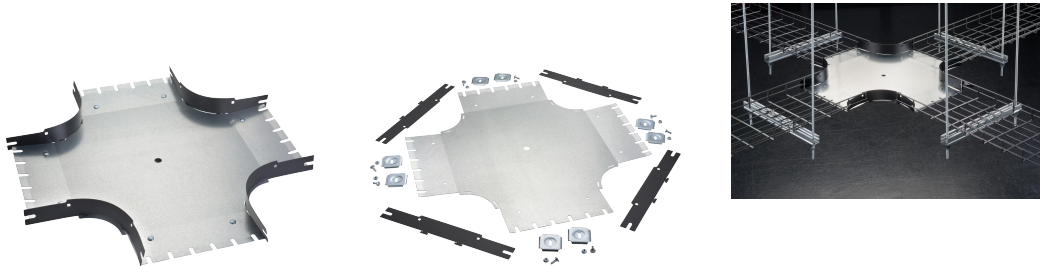

nVent CADDY WBT Performance Cable Tray PreForm is a cleaner, faster and more uniform engineered solution for pathway bends, tees and intersections. The PreForm is a revolutionary, time-saving solution for seamless intersections, ensuring clean engineering, precision with effortless attachment and no cutting or configuring required. This product offers up to 60% reduction in labor and time compared to traditional methods due to the ability to maintain flexibility and cost-effectiveness in any tray pathway retrofit.

## CERTIFICATIONS



## FEATURES

Labor savings up to 60%

Maintains UL classification throughout installation

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/1

Catalog Number	Color	Height	Width	Length	Unit Weight	Certifications
----------------	-------	--------	-------	--------	-------------	----------------

WBTI2X4		2"	3.719"	15.194"	0.411 lb	cUL, UL
WBTI2X4BA	Black	2"	3.719"	15.194"	0.411 lb	
WBTI2X4WH	White	2"	3.719"	15.194"	0.411 lb	
WBTI2X6		2"	5.688"	15.194"	0.617 lb	UL, cUL
WBTI2X6BA	Black	2"	5.688"	15.194"	0.617 lb	
WBTI2X8		2"	7.656"	15.194"	1.029 lb	cUL, UL
WBTI2X8BA	Black	2"	7.656"	15.194"	1.029 lb	
WBTI2X8WH	White	2"	7.656"	15.194"	1.029 lb	
WBTI2X12		2"	11.594"	15.194"	1.44 lb	cUL, UL
WBTI2X12BA	Black	2"	11.594"	15.194"	1.44 lb	
WBTI2X12WH	White	2"	11.594"	15.194"	1.44 lb	
WBTI2X16BA	Black	2"	15.531"	15.194"	2.057 lb	
WBTI2X18		2"	17 1/2"	15.194"	2.469 lb	cUL, UL
WBTI2X18BA	Black	2"	17 1/2"	15.194"	2.469 lb	
WBTI2X20		2"	19.469"	15.194"	2.88 lb	UL, cUL
WBTI2X20BA	Black	2"	19.469"	15.194"	2.88 lb	
WBTI2X24		2"	23.406"	15.194"	3.704 lb	UL, cUL
WBTI2X24BA	Black	2"	23.406"	15.194"	3.704 lb	
WBTI2X24WH	White	2"	23.406"	15.194"	3.704 lb	

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

