


WBT Performance Cable Tray, Round Wire

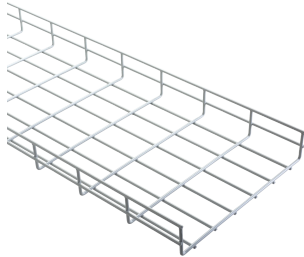

The nVent CADDY WBT Performance Cable Round Wire Tray is a continuous pathway solution to support high-performance cabling systems while providing an ideal foundation for datacom and electrical contractors.

CERTIFICATIONS



FEATURES

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fiber optic

UL Classified as an equipment ground conductor, no field removal of paint required

T-Weld edge wire for cable and installer protection

Mill Certificates are available to document recycled content for possible LEED credits/certification

SPECIFICATIONS

Material: Steel

Table 1/1

Catalog Number	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT2X12	Pregalvanized		2"	12	118"	14 lb
WBT2X12BA	Pregalvanized	Black	2"	12	118"	14 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT2X12EG	Electrogalvaniz ed		2"	12	118"	14 lb
WBT2X12PW	Pregalvanized	Pewter	2"	12	118"	14 lb
WBT2X12WH	Pregalvanized	White	2"	12	118"	14 lb
WBT2X16	Pregalvanized		2"	16	118"	18 lb
WBT2X16BA	Pregalvanized	Black	2"	16	118"	18 lb
WBT2X16EG	Electrogalvaniz ed		2"	16	118"	18 lb
WBT2X16WH	Pregalvanized	White	2"	16	118"	18 lb
WBT2X18	Pregalvanized		2"	18	118"	19 lb
WBT2X18BA	Pregalvanized	Black	2"	18	118"	19 lb
WBT2X18EG	Pregalvanized		2"	18	118"	19 lb
WBT2X18PW	Pregalvanized	Pewter	2"	18	118"	19 lb
WBT2X18WH	Pregalvanized	White	2"	18	118"	19 lb
WBT2X20	Pregalvanized		2"	20	118"	21.59 lb
WBT2X20BA	Pregalvanized	Black	2"	20	118"	21.59 lb
WBT2X20EG	Electrogalvaniz ed		2"	20	118"	21.59 lb
WBT2X24	Pregalvanized		2"	24	118"	24 lb
WBT2X24BA	Pregalvanized	Black	2"	24	118"	24 lb
WBT2X24EG	Pregalvanized		2"	24	118"	24 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT2X24PW	Pregalvanized	Pewter	2"	24	118"	24 lb
WBT2X24WH	Pregalvanized	White	2"	24	118"	24 lb
WBT2X4	Pregalvanized		2"	4	118"	8 lb
WBT2X4BA	Pregalvanized	Black	2"	4	118"	8 lb
WBT2X4EG	Pregalvanized		2"	4	118"	8 lb
WBT2X4PW	Pregalvanized	Pewter	2"	4	118"	8 lb
WBT2X4WH	Pregalvanized	White	2"	4	118"	8 lb
WBT2X6	Pregalvanized		2"	6	118"	9 lb
WBT2X6BA	Pregalvanized	Black	2"	6	118"	9 lb
WBT2X6EG	Electrogalvaniz ed		2"	6	118"	9 lb
WBT2X6PW	Pregalvanized	Pewter	2"	6	118"	9 lb
WBT2X6WH	Pregalvanized	White	2"	6	118"	9 lb
WBT2X8	Pregalvanized		2"	8	118"	9.78 lb
WBT2X8BA	Pregalvanized	Black	2"	8	118"	10 lb
WBT2X8EG	Electrogalvaniz ed		2"	8	118"	10 lb
WBT2X8PW	Pregalvanized	Pewter	2"	8	118"	9.78 lb
WBT2X8WH	Pregalvanized	White	2"	8	118"	9.78 lb
WBT4X12	Pregalvanized		4"	12	118"	18 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT4X12BA	Pregalvanized	Black	4"	12	118"	18 lb
WBT4X12EG	Electrogalvanized		4"	12	118"	18 lb
WBT4X12PW	Pregalvanized	Pewter	4"	12	118"	18 lb
WBT4X12WH	Pregalvanized	White	4"	12	118"	18 lb
WBT4X16	Pregalvanized		4"	16	118"	22 lb
WBT4X16BA	Pregalvanized	Black	4"	16	118"	22 lb
WBT4X16EG	Electrogalvanized		4"	16	118"	22 lb
WBT4X16WH	Pregalvanized	White	4"	16	118"	22 lb
WBT4X18	Pregalvanized		4"	18	118"	23 lb
WBT4X18BA	Pregalvanized	Black	4"	18	118"	23 lb
WBT4X18EG	Electrogalvanized		4"	18	118"	23 lb
WBT4X18PW	Pregalvanized	Pewter	4"	18	118"	23 lb
WBT4X18WH	Pregalvanized	White	4"	18	118"	23 lb
WBT4X20	Pregalvanized		4"	20	118"	24 lb
WBT4X20BA	Pregalvanized	Black	4"	20	118"	24 lb
WBT4X20EG	Electrogalvanized		4"	20	118"	24 lb
WBT4X24	Pregalvanized		4"	24	118"	29 lb
WBT4X24BA	Pregalvanized	Black	4"	24	118"	29 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT4X24EG	Electrogalvaniz ed		4"	24	118"	29 lb
WBT4X24PW	Pregalvanized	Pewter	4"	24	118"	29 lb
WBT4X24WH	Pregalvanized	White	4"	24	118"	29 lb
WBT4X4	Pregalvanized		4"	4	118"	10 lb
WBT4X4BA	Pregalvanized	Black	4"	4	118"	10 lb
WBT4X4EG	Electrogalvaniz ed		4"	4	118"	10 lb
WBT4X4PW	Pregalvanized	Pewter	4"	4	118"	10 lb
WBT4X4WH	Pregalvanized	White	4"	4	118"	10 lb
WBT4X6	Pregalvanized		4"	6	118"	11 lb
WBT4X6BA	Pregalvanized	Black	4"	6	118"	11 lb
WBT4X6EG	Electrogalvaniz ed		4"	6	118"	11 lb
WBT4X6PW	Pregalvanized	Pewter	4"	6	118"	11 lb
WBT4X6WH	Pregalvanized	White	4"	6	118"	11 lb
WBT4X8	Pregalvanized		4"	8	118"	14 lb
WBT4X8BA	Pregalvanized	Black	4"	8	118"	14 lb
WBT4X8EG	Electrogalvaniz ed		4"	8	118"	14 lb
WBT4X8PW	Pregalvanized	Pewter	4"	8	118"	14 lb
WBT4X8WH	Pregalvanized	White	4"	8	118"	14 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT6X12	Pregalvanized		6"	12	118"	22 lb
WBT6X12BA	Pregalvanized	Black	6"	12	118"	22 lb
WBT6X12EG	Electrogalvanized		6"	12	118"	22 lb
WBT6X12WH	Pregalvanized	White	6"	12	118"	22 lb
WBT6X16	Pregalvanized		6"	16	118"	24 lb
WBT6X16BA	Pregalvanized	Black	6"	16	118"	24 lb
WBT6X16EG	Electrogalvanized		6"	16	118"	24 lb
WBT6X18	Pregalvanized		6"	18	118"	25 lb
WBT6X18BA	Pregalvanized	Black	6"	18	118"	25 lb
WBT6X18EG	Pregalvanized		6"	18	118"	25 lb
WBT6X18PW	Pregalvanized	Pewter	6"	18	118"	25 lb
WBT6X18WH	Pregalvanized	White	6"	18	118"	25 lb
WBT6X20	Pregalvanized		6"	18	118"	29 lb
WBT6X20BA	Pregalvanized	Black	6"	20	118"	29 lb
WBT6X20EG	Electrogalvanized		6"	20	118"	29 lb
WBT6X24	Pregalvanized		6"	24	118"	32.01 lb
WBT6X24BA	Pregalvanized	Black	6"	24	118"	32.01 lb
WBT6X24EG	Electrogalvanized		6"	24	118"	22 lb

CatalogNumber	Finish	Color	Height (H)	Width (W)	Length (L)	Unit Weight
WBT6X24WH	Pregalvanized	White	6"	24	118"	32.01 lb
WBT6X8	Pregalvanized		6"	8	118"	18 lb
WBT6X8BA	Pregalvanized	Black	6"	8	118"	18 lb
WBT6X8EG	Electrogalvanized		6"	8	118"	18 lb
WBT6X8WH	Pregalvanized	White	6"	8	118"	18 lb

2" DEEP TRAY	
Tray Size	Splice Qty
2X4	2
2X6	3
2X8	3
2X12	3
2X16	4
2X18	4
2X20	4
2X22	5
2X24	5
2X26	6
2X28	6
2X30	6
2X32	7
2X34	7
2X36	8
2X38	8
2X40	9
These products are also available for Shaped Cable Tray and can be found by including an S to the end of any part number above	

4" DEEP TRAY	
Tray Size	Splice Qty
4X4	3
4X6	3
4X8	3
4X12	3
4X16	4
4X18	4
4X20	4
4X22	4
4X24	5
4X28	5
4X30	6
4X32	6
4X34	6
4X36	7
These products are also available for Shaped Cable Tray and can be found by including an S to the end of any part number above	

6" DEEP TRAY	
Tray Size	Splice Qty
6X8	3
6X12	3
6X16	3
6X18	4
6X20	4
6X22	4
6X24	4
6X26	5
6X28	5
6X30	5
6X32	6
6X34	6
6X36	7
These products are also available for Shaped Cable Tray and can be found by including an S to the end of any part number above	

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

