


CableTek Horizontal Cable Manager

Data Solutions

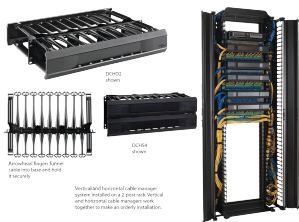

The CableTek Horizontal Cable Manager features heavy-duty endposts, arrowhead fingers and tool-less mounting to easily route Cat 5e, 6 and 6A cable horizontally in standard 19-in. cabinets or on 2- or 4-post open frame racks.

INDUSTRY STANDARDS

EIA 310-D

FEATURES

- Snap-in mounting provision holds cable manager in place while mounting screws are installed
- Robust arrowhead fingers are shaped to funnel cables into base and are made of black composite material
- Robust rounded end posts support cable as it enters and leaves cable manager and maintains proper cable bend radius
- Deep cable compartments allow maximum cable density
- Rounded edges throughout protect cable jackets from damage
- Pass-through holes on double-sided models protect cable while facilitating routing between front and back sides
- Single- and double-sided units provide high cable capacity, including 5e, 6 and 6A cables
- 1 RU and 2 RU heights allow greater flexibility in optimizing rack capacity
- Removable hinged cover opens top or bottom, snaps closed for assured cable protection and professional appearance
- Double-sided model has covers on both front and back
- Covers stay open during installation and maintenance procedures
- Horizontal and vertical cable managers designed as a system for streamlined appearance and improved functionality
- Combination head 10-32 and 12-24 screws included for mounting
- Made of UL listed black composite material

SPECIFICATIONS

Table 1/4

Catalog Number	Article Number	Height	Width	Depth	Material	Finish
----------------	----------------	--------	-------	-------	----------	--------

DCHS1	17241				ABS	Smooth Matte
DCHD2	17243				ABS	Smooth Matte
DCHS2	17242	7.9in	3.47in	18.93in	ABS	Smooth Matte
DCHS4	26292				ABS	Smooth Matte

Table 2/4

Catalog Number	Article Number	Color	Color Code	Back Cross-Section Area	Fill Rate, Back Cable, Cat 5e \times 0.22 in	Fill Rate, Back Cable, Cat 6 \times 0.25 in
DCHS1	17241	Jet Black	RAL 9005			
DCHD2	17243	Jet Black	RAL 9005	14.1in ²	223	172
DCHS2	17242	Jet Black	RAL 9005			
DCHS4	26292	Jet Black	RAL 9005			

Table 3/4

Catalog Number	Article Number	Fill Rate, Back Cable, Cat 6A \times 0.30 in	Rack Units	Front Cross-Section Area	Fill Rate, Front Cable, Cat 5e \times 0.22 in	Fill Rate, Front Cable, Cat 6 \times 0.25 in
DCHS1	17241		1U	4.2in ²	66	57
DCHD2	17243	119	2U	13.2in ²	208	161
DCHS2	17242		2U	13.2in ²	208	161
DCHS4	26292		4U	26.9in ²	416	322

Table 4/4

Catalog Number	Article Number	Fill Rate, Front Cable, Cat 6A \times 0.30 in
DCHS1	17241	35
DCHD2	17243	112

Catalog Number	Article Number	Fill Rate, Front Cable, Cat 6A 0.30 in
DCHS2	17242	112
DCHS4	26292	224

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE