


Door-Mount PDU LCD Display

Data Solutions

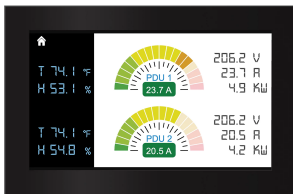

Smart, stylish Door-Mount PDU LCD Display externally monitors the PDU metrics inside the cabinet without opening the door to physically review the PDU's metrics. Easy magnetic mounting installation not requiring any cabinet door cutout. Touchscreen can be installed horizontally or vertically and has plug-n-play connectivity.

FEATURES

Saves time monitoring PDU metrics from outside the cabinet

Prevents entering cabinet to monitor PDU metrics

Easy magnetic mounting installation

No cabinet door cutout required

Optional mounting screw kit included

Display horizontally or vertically

Plug-n-Play connectivity

Resistive touch screen

Smart and stylish design

With corresponding PDU connected sensors, it monitors voltage, current, power, temperature, humidity and air flow

4.3-inch (109mm) display size

480 x 272 display resolution

RJ-11 cables connection

SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Height	Width	Depth	Material	Color
----------------	----------------	--------	-------	-------	----------	-------

LCD4INDRMT	39385	5.24in	3.54in	0.67in	Plastic	Black
------------	-------	--------	--------	--------	---------	-------

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE