

# Low Voltage Insulator, Imperial , 2", 2" Hex Width, 2.31", 3/8 UNC

## Data Solutions

### CATALOG NUMBER

**IS02-38-16**



### CERTIFICATIONS



### FEATURES

Great stability of electrical and mechanical parameters

High resistance to leakage current

UL® Recognized in E125470 and evaluated for dielectric withstand rating of 1,500 VAC/DC

Halogen free

RoHS compliant

### PRODUCT ATTRIBUTES

Article Number: 559680

Material: Glass Fibre Reinforced Polyester; Steel

Finish: Electrogalvanized

Working Temperature: -40 to 266°F

Flammability Rating: UL® 94V-0

Height (H): 2in

Hex Width (W): 2in

Depth (D): 2.31in

Thread Size (TS): 3/8" UNC

Thread Depth (TD): 0.5625in

Diameter (Ø): 1.65in

Insulation Voltage: 2300

Static Load 1 (F1): 3000lb


Static Load 2 (F2): 1200lb

Unit Weight: 0.42lb

## ADDITIONAL PRODUCT DETAILS

Creepage and clearance distances need to be in accordance with the relevant application standard.

## DIAGRAMS

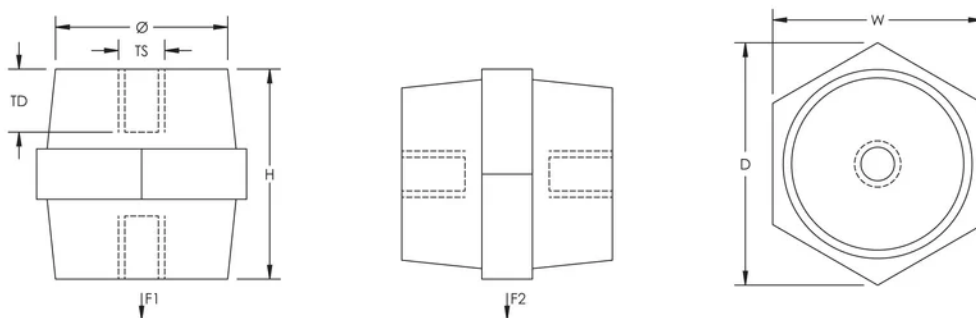

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**