

nVent CADDY Cablecat J-Hook with Hammer-On Flange Clip, Swivel

Data Solutions



CERTIFICATIONS



FEATURES

Hammer-on beam clamp with attached nVent CADDY Cablecat J-Hook

Supports low voltage cables

Rotates 360 degrees to support various directional runs of cable

SPECIFICATIONS

Finish: Pregalvanized; nVent CADDY Armour


Material: Steel; Spring Steel

Table 1/1

Catalog Number	Diameter (Ø)	Flange Thickness (FT)
CAT1224	0.75in	0.125in

Catalog Number	Diameter (Ø)	Flange Thickness (FT)
CAT1258	0.75in	0.3125 – 0.5in
CAT12912	0.75in	0.5625 – 0.75in

DIAGRAMS

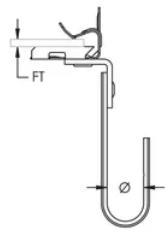

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE