

nVent CADDY Cat HP J-Hook Straight Bracket

Data Solutions



CERTIFICATIONS



FEATURES

Can be attached to various nVent CADDY fasteners or screwed directly to a wall

Ideal for attaching to concrete, steel or wood surfaces

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations


nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Hole Size (HS)	Static Load (F)
CATHPS4	Spring Steel	nVent CADDY Armour	0.25in	200lb

DIAGRAMS

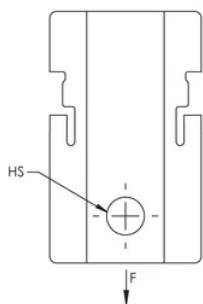

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE