


RIM-C Channel Panel

Data Solutions

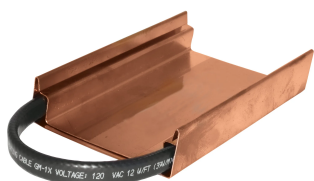

nVent RAYCHEM RIM-C channel panels are used to provide a heated channel for snow melt to flow. RIM2-C panels embed 2 runs of high wattage self-regulating cables in metal panels to form a channel. These are typically used to direct snow melt from one section of the roof to another, usually the drain or eave.

FEATURES

Simple and fast to install

Aesthetically pleasing solution: by concealing the heating cable, complete snow melt from the drain to the roof eave

Available in a wide variety of colors

Long term roof deicing solution: by mechanically protecting the heating cable

High performance and reliable solution: for heavy snow load areas

Energy efficient, self-regulating heating cable plus advanced UL and CSA Certified control systems

Reliable during long life: 20 year product warranty available

Maintenance free

SPECIFICATIONS

Heating Capacity: 24W/ft

Cable Type: Self-Regulating

Table 1/1

Catalog Number	Nominal Voltage	Color
F6221-AL-01-1	120V	Slate Gray
F6221-AL-01-2	240V	Slate Gray

Catalog Number	Nominal Voltage	Color
F6221-AL-02-1	120V	Stone White
F6221-AL-02-2	240V	Stone White
F6221-AL-03-1	120V	Bone White
F6221-AL-03-2	240V	Bone White
F6221-AL-04-1	120V	Almond
F6221-AL-04-2	240V	Almond
F6221-AL-05-1	120V	Sandstone
F6221-AL-05-2	240V	Sandstone
F6221-AL-06-1	120V	Sierra Tan
F6221-AL-06-2	240V	Sierra Tan
F6221-AL-07-1	120V	Teal
F6221-AL-07-2	240V	Teal
F6221-AL-08-1	120V	Regal Blue
F6221-AL-08-2	240V	Regal Blue
F6221-AL-09-1	120V	Sky Blue
F6221-AL-09-2	240V	Sky Blue
F6221-AL-10-1	120V	Sherwood Green
F6221-AL-10-2	240V	Sherwood Green

Catalog Number	Nominal Voltage	Color
F6221-AL-11-1	120V	Hartford Green
F6221-AL-11-2	240V	Hartford Green
F6221-AL-12-1	120V	Hemlock Green
F6221-AL-12-2	240V	Hemlock Green
F6221-AL-13-1	120V	Patina Green
F6221-AL-13-2	240V	Patina Green
F6221-AL-14-1	120V	Dark Ivy
F6221-AL-14-2	240V	Dark Ivy
F6221-AL-15-1	120V	Brandywine
F6221-AL-15-2	240V	Brandywine
F6221-AL-16-1	120V	Regal Red
F6221-AL-16-2	240V	Regal Red
F6221-AL-17-1	120V	Colonial Red
F6221-AL-17-2	240V	Colonial Red
F6221-AL-18-1	120V	Terra Cotta
F6221-AL-18-2	240V	Terra Cotta
F6221-AL-19-1	120V	Dark Bronze
F6221-AL-19-2	240V	Dark Bronze

Catalog Number	Nominal Voltage	Color
F6221-AL-20-1	120V	Extra Dark Bronze
F6221-AL-20-2	240V	Extra Dark Bronze
F6221-AL-21-1	120V	Mansard Brown
F6221-AL-21-2	240V	Mansard Brown
F6221-AL-22-1	120V	Medium Bronze
F6221-AL-22-2	240V	Medium Bronze
F6221-AL-23-1	120V	Matte Black
F6221-AL-23-2	240V	Matte Black
F6221-AL-24-1	120V	Classic Copper
F6221-AL-24-2	240V	Classic Copper
F6221-AL-25-1	120V	Silver Metallic
F6221-AL-25-2	240V	Silver Metallic
F6221-AL-26-1	120V	Champagne Metallic
F6221-AL-26-2	240V	Champagne Metallic
F6221-AL-27-1	120V	Cityscape
F6221-AL-27-2	240V	Cityscape
F6221-AL-28-1	120V	Charcoal Gray
F6221-AL-28-2	240V	Charcoal Gray

Catalog Number	Nominal Voltage	Color
F6221-AL-29-1	120V	Tropical Patina
F6221-AL-29-2	240V	Tropical Patina
F6221-AL-30-1	120V	Electric Blue
F6221-AL-30-2	240V	Electric Blue
F6221-AL-31-1	120V	Award Blue
F6221-AL-31-2	240V	Award Blue
F6221-AL-32-1	120V	Granite Green
F6221-AL-32-2	240V	Granite Green
F6221-AL-50-1	120V	040 Mill Finish
F6221-AL-50-2	240V	040 Mill Finish
F6221-CU-70-1	120V	Copper
F6221-CU-70-2	240V	Copper

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE