


Varistar 19" Shelf, Stationary, 75 kg

Data Solutions

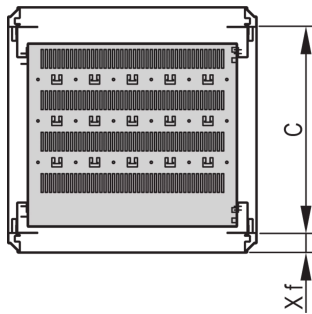

Varistar 19" Shelf, Stationary, 75 kg.

CERTIFICATIONS



FEATURES

Static load-carrying capacity 75 kg

St, 1.5 mm

Incl. GND/grounding

Width 495 mm

For mounting on four 19" panel/slide mounts

SPECIFICATIONS

Product Type: Shelf

Material: Steel

Table 1/1

Catalog Number	Package Quantity	Color	Color Code	Finish	Type
22130-309	1	Light Grey	RAL 7035	Powder Coated	Full Depth

Catalog Number	Package Quantity	Color	Color Code	Finish	Type
21130-302	1	Black Grey	RAL 7021	Powder Coated	Recessed Depth
21130-303	1	Black Grey	RAL 7021	Powder Coated	Full Depth
21130-304	1	Black Grey	RAL 7021	Powder Coated	Recessed Depth
21130-305	1	Black Grey	RAL 7021	Powder Coated	Full Depth
21130-309	1	Black Grey	RAL 7021	Powder Coated	Full Depth
22130-302	1	Light Grey	RAL 7035	Powder Coated	Recessed Depth
22130-303	1	Light Grey	RAL 7035	Powder Coated	Full Depth
22130-304	1	Light Grey	RAL 7035	Powder Coated	Recessed Depth
22130-305	1	Light Grey	RAL 7035	Powder Coated	Full Depth

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE