

1 Hole Offset Lug



FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type LA connections only

SPECIFICATIONS

Table 1/3

Catalog Number	Material	Finish	Type	Height (H)	Length (L)	Width (W)
B101CEOL	Copper	Tinned	NEMA®	0.63"	2 1/2"	1"
B101CEOL001	Copper	Tinned	NEMA®	0.63"	2 1/2"	1"
B101QQOL	Copper	Tinned	NEMA®	0.62"	2.52"	1"
B101DEOL	Copper	Tinned	NEMA®	0.69"	2.69"	1"
B101SQOL	Copper	Tinned	NEMA®	0.56"	2.68"	1"
B305SS	Stainless Steel 304 (EN 1.4301)		Non-NEMA®	0.79"	3.6"	1.18"

CatalogNumber	Material	Finish	Type	Height (H)	Length (L)	Width (W)
B305TC	Copper	Tinned	Non-NEMA®	0.79"	3.6"	1.18"
B101EEOL	Copper	Tinned	NEMA®	3/4"	3"	1"
B101EFOL001	Copper	Tinned	NEMA®	3/4"	3"	1 1/4"
B101EGOL	Copper	Tinned	NEMA®	3/4"	3 1/4"	1 1/2"
B101GGOL	Copper	Tinned	NEMA®	1 1/4"	4 1/4"	1 1/2"
B101GHOL	Copper	Tinned	NEMA®	1 1/4"	5"	2"
B101GHOL001	Copper	Tinned	NEMA®	1 1/4"	5"	2"

Table 2/3

Catalog Number	Thickness (T)	A	B	C	Hole Size (HS)	Angle (a)
B101CEOL	0.12"	1/2"	1"	0.88"	0.44"	45 °
B101CEOL001	0.12"	1/2"	1"	0.88"	0.69"	45 °
B101QQOL	0.12"	0.47"	0.87"	3/4"	0.44"	45 °
B101DEOL	0.19"	0.56"	1.13"	0.88"	0.56"	45 °
B101SQOL	0.19"	0.55"	1.1"	0.81"	0.56"	45 °
B305SS	0.2"	0.59"	1.33"	1.57"	0.67"	45 °
B305TC	0.2"	0.59"	1.33"	1.57"	0.67"	45 °
B101EEOL	1/4"	0.62"	1.28"	1.06"	0.56"	45 °
B101EFOL001	1/4"	0.62"	1.28"	1.06"	0.69"	45 °

CatalogNumber	Thickness (T)	A	B	C	Hole Size (HS)	Angle (a)
B101EGOL	1/4"	3/4"	1 1/2"	1.06"	0.69"	45 °
B101GGOL	0.38"	3/4"	1 3/4"	1 1/2"	0.69"	45 °
B101GHOL	0.38"	1"	2.38"	1 1/2"	0.69"	45 °
B101GHOL001	0.38"	1"	2.38"	1 1/2"	0.81"	45 °


Table 3/3

Catalog Number	Equivalent Conductor Size
B101CEOL	159.12kcmil
B101CEOL001	159.12kcmil
B101QQOL	159kcmil
B101DEOL	238.69kcmil
B101SQOL	239kcmil
B305SS	300.43kcmil
B305TC	300.43kcmil
B101EEOL	318.25kcmil
B101EFOL001	397.81kcmil
B101EGOL	477.38kcmil
B101GGOL	716.06kcmil
B101GHOL	954.75kcmil
B101GHOL001	954.75kcmil

ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

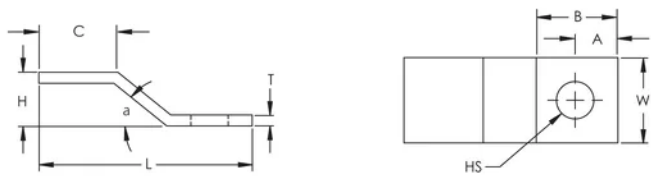

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE