

2 Hole Offset Lug



FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type LA connections only

SPECIFICATIONS

Material: Copper

Finish: Tinned

Table 1/2

Catalog Number	Type	Height (H)	Length (L)	Width (W)	Thickness (T)	A
B103AAOL003	Non-NEMA®	0.56"	3 3/4"	1/2"	0.06"	0.62"
B102CEOL	NEMA®	0.63"	4 1/2"	1"	0.12"	0.62"
B102CEOL001	NEMA®	0.63"	4 1/2"	1"	0.12"	0.62"
B103CEOL003	Non-NEMA®	0.63"	3.43"	1"	0.12"	0.44"
PBB102CEOL	NEMA®	0.63"	4 1/2"	1"	0.12"	0.62"

CatalogNumber	Type	Height (H)	Length (L)	Width (W)	Thickness (T)	A
B102DEOL	NEMA®	0.69"	4 1/2"	1"	0.19"	0.62"
B103DEOL	Non-NEMA®	1.07"	4 1/2"	1"	0.19"	0.62"
B102EEOL	NEMA®	3/4"	4 3/4"	1"	1/4"	0.62"
B102EFOL	NEMA®	3/4"	4 3/4"	1 1/4"	1/4"	0.62"
B102EGOL	NEMA®	3/4"	4 3/4"	1 1/2"	1/4"	0.62"
B102EHOL	NEMA®	3/4"	5"	2"	1/4"	0.62"
B103EEOL003	Non-NEMA®	3/4"	2.03"	1"	1/4"	0.44"
B103EGOL001	Non-NEMA®	3/4"	3.62"	1 1/2"	1/4"	0.44"
B102GGOL	NEMA®	1 1/4"	5.88"	1 1/2"	0.38"	0.62"
B102GHOL	NEMA®	1 1/4"	5.88"	2"	0.38"	0.62"
B102JHOL	NEMA®	1.38"	5.88"	2"	1/2"	0.62"

Table 2/2


Catalog Number	B	C	D	Hole Size (HS)	Angle (a)	Equivalent Conductor Size
B103AAOL003	1"	2 1/4"	0.88"	1/4"	45 °	39.78kcmil
B102CEOL	1 3/4"	3"	0.88"	0.56"	45 °	159.12kcmil
B102CEOL001	1 3/4"	3"	0.88"	0.31"	45 °	159.12kcmil
B103CEOL003	1"	1.93"	0.88"	0.44"	45 °	159.12kcmil
PBB102CEOL	1 3/4"	3"	0.88"	0.56"	45 °	159.12kcmil
B102DEOL	1 3/4"	3"	0.88"	0.56"	45 °	238.69kcmil

CatalogNumber	B	C	D	Hole Size (HS)	Angle (a)	Equivalent Conductor Size
B103DEOL	1"	1.93"	0.88"	0.44"	45 °	238.69kcmil
B102EEOL	1 3/4"	3"	1.06"	0.56"	45 °	318.25kcmil
B102EFOL	1 3/4"	3"	1.06"	0.56"	45 °	397.81kcmil
B102EGOL	1 3/4"	3"	1.06"	0.56"	45 °	477kcmil
B102EHOL	1 3/4"	3"	1 1/4"	0.56"	45 °	636.5kcmil
B103EEOL003	1"	2.03"	1.06"	0.44"	45 °	318.25kcmil
B103EGOL001	1"	2"	1"	0.44"	45 °	477.38kcmil
B102GGOL	1 3/4"	3 1/4"	1 1/2"	0.56"	45 °	716.06kcmil
B102GHOL	1 3/4"	3 1/4"	1 1/2"	0.56"	45 °	954.75kcmil
B102JHOL	1 3/4"	3 1/4"	2"	0.56"	45 °	1273kcmil

ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

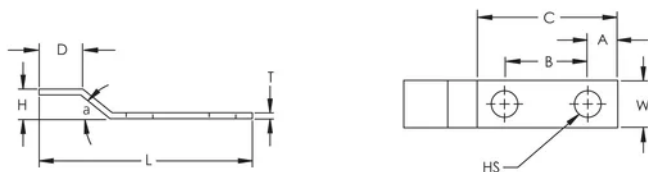

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE