

Compression Coupler for Copper-Bonded Ground Rod, Pointed



CERTIFICATIONS



FEATURES

Threadless compression coupler for use with pointed copper-bonded ground rods

Inside of coupler is tapered so ground rod compresses during installation to form an irreversible conductive connection

SPECIFICATIONS

Material: Silicon Bronze


Table 1/1

Catalog Number	Ground Rod Diameter, Nominal	Length (L)	Unit Weight	Complies With	Certifications
CC12F	1/2"	2 3/4"	0.29 lb		UL, CSA-US, cUL, CSA
CC58	5/8"	2 3/4"	0.32 lb	IEC® EN 62561-2	UL, CSA, cUL, CSA-US, RUS
CC34	3/4"	2 3/4"	0.44 lb	IEC® EN 62561-2	CSA, UL, cUL, CSA-US

ADDITIONAL PRODUCT DETAILS

IEC® EN 62561-2 supercedes EN 50164-2.

DIAGRAMS

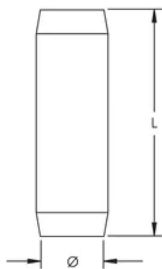

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE