

# Drill Distance Gauge, Four Plates



## FEATURES

Used for making precise drill hole spacings of  $\pm 1$  mm (0.039")

Common applications include fishplates and insulated rail joints

## SPECIFICATIONS

**Drill Guide Included:** No  
**Material:** Steel

Table 1/2


Catalog Number	Rail Type	Length (L)	Width (W)	Height (H)	A	B
DDGNP4AM40	NP4AM	15 3/4"	3.46"	1.97"	1.57"	1.57"
DDGNP4AM45	NP4AM	16.34"	3.46"	1.97"	1.77"	1.77"
DDG750900750	STR40	20.47"	3.46"	1.97"	2.95"	3.54"
DDG570660570	S49	14.76"	4.72"	2.36"	2.24"	2.6"

Table 2/2

Catalog Number	C
DDGNP4AM40	1.57"

Catalog Number	C
DDGNP4AM45	1.77"
DDG750900750	2.95"
DDG570660570	2.24"

### DIAGRAMS

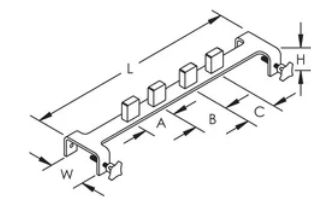

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE