

Female-Female Swivel Adaptor, Imperial Thread



CERTIFICATIONS



FEATURES

Allows air terminal to be positioned vertically when base is on a sloping roof

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)	Length 2 (L2)
LPA2832F2F	Aluminum		1/2" UNC	1/2" UNC	1 3/4"	1 3/4"
LPA2842F5F	Aluminum		1/2" UNC	5/8" UNC	1 3/4"	1 3/4"
LPA2855F5F	Aluminum		5/8" UNC	5/8" UNC	1 3/4"	1 3/4"
LPS2832F2F	Stainless Steel 304 (EN 1.4301)		1/2" UNC	1/2" UNC	1 3/4"	1 3/4"


CatalogNumber	Material	Finish	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Length 1 (L1)	Length 2 (L2)
LPS2842F5F	Stainless Steel 304 (EN 1.4301)		1/2" UNC	5/8" UNC	1 3/4"	1 3/4"
LPS2855F5F	Stainless Steel 304 (EN 1.4301)		5/8" UNC	5/8" UNC	1 3/4"	1 3/4"
LPC2813F3F	Copper		3/8" UNC	3/8" UNC	1 3/4"	1 3/4"
LPC281L3F3F	Copper	Tinned	3/8" UNC	3/8" UNC	1 3/4"	1 3/4"
LPC2823F2F	Copper		3/8" UNC	1/2" UNC	1 3/4"	1 3/4"
LPC282L3F2F	Copper	Tinned	3/8" UNC	1/2" UNC	1 3/4"	1 3/4"
LPC2832F2F	Copper		1/2" UNC	1/2" UNC	1 3/4"	1 3/4"
LPC2842F5F	Copper		1/2" UNC	5/8" UNC	1 3/4"	1 3/4"
LPC2855F5F	Copper		5/8" UNC	5/8" UNC	1 3/4"	1 3/4"
LPC285L5F5F	Copper	Tinned	5/8" UNC	5/8" UNC	1 3/4"	1 3/4"

Table 2/2

Catalog Number	Unit Weight	Certifications
LPA2832F2F	0.14 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPA2842F5F	0.14 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPA2855F5F	0.14 lb	
LPS2832F2F	0.15 lb	
LPS2842F5F	0.15 lb	
LPS2855F5F	0.15 lb	

Catalog Number	Unit Weight	Certifications
LPC2813F3F	0.17 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPC281L3F3F	0.17 lb	
LPC2823F2F	0.17 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPC282L3F2F	0.17 lb	
LPC2832F2F	0.17 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPC2842F5F	0.17 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPC2855F5F	0.17 lb	E202878-Combined_CoC, E202878-Combined_CoC
LPC285L5F5F	0.17 lb	

DIAGRAMS

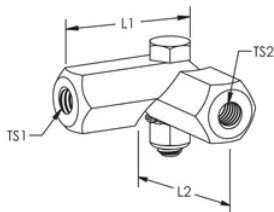

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE