


Joint Bond T6 Complete Welder Pair, Signal

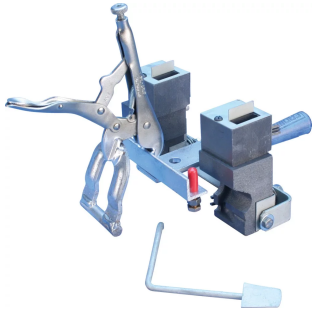

FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Material: Steel;Graphite;Thermoplastic

Table 1/1

Catalog Number	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
SBHFT6A	Head Free	3/16" Bondstrand	0.19"	6 1/2"	T6
SBHFT6C	Head Free	3/16" Bondstrand	0.19"	7 1/2"	T6
SBHFT6D	Head Free	3/16" Bondstrand	0.19"	9 3/4"	T6
SBTBT6A	1" Tab	3/16" Bondstrand	0.19"	6 1/2"	T6
SBTBT6C	3/4" Tab	3/16" Bondstrand	0.19"	7 1/2"	T6

Catalog Number	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
SBTBT6D	1" Tab	3/16" Bondstrand	0.19"	9 3/4"	T6
SBXST6A	3/4" XS	3/16" Bondstrand	0.19"	6 1/2"	T6
SBXST6C	3/4" XS	3/16" Bondstrand	0.19"	7 1/2"	T6
SBXST6D	3/4" XS	3/16" Bondstrand	0.19"	9 3/4"	T6
SBST6X2	1" Tab	35 mm ² Ropelay	0.3"	7"	T6
SBHFT6B	Head Free	5/16" Bondstrand	0.31"	7"	T6
SBTBT6B	1" Tab	5/16" Bondstrand	0.31"	7"	T6
SBTBT6E	1" Tab	5/16" Bondstrand	0.31"	9 3/4"	T6

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE