

Non-Insulated Stranded Conductor



CERTIFICATIONS



FEATURES

Stranded pure electrolytic copper cable conductors for a variety of applications

Stranded grounded conductor cut into standard lengths for easy field installation

SPECIFICATIONS

Conductor Type: Concentric

Material: Copper

Table 1/2

Catalog Number	Number of Wires	Wire Diameter	Diameter (Ø)	Length (L)	Cross Section	Conductor Size
A800A09F65	19	0.08"	0.42"	65'	133kcmil	2/0 Stranded
A800A22F100	19	0.11"	0.53"	100'	211.6kcmil	4/0 Stranded

Table 2/2


Catalog Number	Unit Weight
----------------	-------------

A800A09F65	26.7 lb
A800A22F100	65 lb

ADDITIONAL PRODUCT DETAILS

Outer diameter dimensions are approximate.

DIAGRAMS

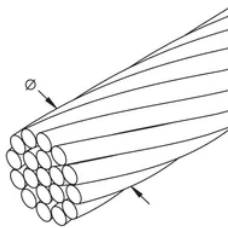

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE