

nVent ERICO PermaGround Surface Bonding Jumper



nVent ERICO PermaGround Surface Bonding Jumper is a conductor used to ensure electrical continuity and a low-impedance path for fault currents between metal parts that need to be electrically connected.

CERTIFICATIONS



FEATURES

Copper

SPECIFICATIONS

Material: Copper

Table 1/2

Catalog Number	Conductor Type	Conductor Material	Connector Finish	Wire Size	Height (H)	Length (L)
SBJ-516-72	Stranded	Copper	Tinned	#6	10.134"	1845.818"
SBJ-14-1012	Stranded	Copper	Tinned	#6	10.134"	283.718"
SBJ-516-1012	Stranded	Copper	Tinned	#6	10.134"	283.718"


CatalogNumber	ConductorType	ConductorMaterial	ConnectorFinish	Wire Size	Height (H)	Length (L)
SBJ-14-12	Stranded	Copper	Tinned	#6	10.134"	321.818"
SBJ-516-32	Stranded	Copper	Tinned	#6	10.134"	829.818"
SBJ-14-712	Stranded	Copper	Tinned	#6	10.134"	207.518"
SBJ-38-712	Stranded	Copper	Tinned	#6	10.134"	207.518"
SBJ-516-40	Stranded	Copper	Tinned	#6	10.134"	1033.018"
SBJ-516-712	Stranded	Copper	Tinned	#6	10.134"	207.518"
SBJ-38-6	Stranded	Copper	Tinned	#6	10.134"	169.418"
SBJ-516-6	Stranded	Copper	Tinned	#6	10.134"	169.418"
SBJ-14-6	Stranded	Copper	Tinned	#6	10.134"	169.418"
SBJ-38-9	Stranded	Copper	Tinned	#6	10.134"	245.618"
SBJ-516-9	Stranded	Copper	Tinned	#6	10.134"	245.618"
SBJ-38-18	Stranded	Copper	Tinned	#6	10.134"	474.218"
SBJ-14-24	Stranded	Copper	Tinned	#6	10.134"	626.618"
SBJ-14-32	Stranded	Copper	Tinned	#6	10.134"	829.818"
SBJ-14-36	Stranded	Copper	Tinned	#6	10.134"	931.418"

Table 2/2

Catalog Number	Width (W)	Unit Weight
SBJ-516-72	17.018"	0.15 lb
SBJ-14-1012	17.018"	0.17 lb

Catalog Number	Width (W)	Unit Weight
SBJ-516-1012	17.018"	0.17 lb
SBJ-14-12	17.018"	0.19 lb
SBJ-516-32	17.018"	0.48 lb
SBJ-14-712	17.018"	0.605 lb
SBJ-38-712	17.018"	0.605 lb
SBJ-516-40	17.018"	0.6 lb
SBJ-516-712	17.018"	0.61 lb
SBJ-38-6	17.018"	0.649 lb
SBJ-516-6	17.018"	0.68 lb
SBJ-14-6	17.018"	0.7 lb
SBJ-38-9	17.018"	0.879 lb
SBJ-516-9	17.018"	0.89 lb
SBJ-38-18	17.018"	1.443 lb
SBJ-14-24	17.018"	1.921 lb
SBJ-14-32	17.018"	2.559 lb
SBJ-14-36	17.018"	2.878 lb

DIAGRAMS

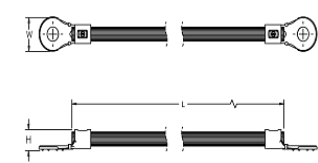

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE