

nVent ERICO Railclips, Hammer-On, Conductor Parallel Outside



FEATURES

"Hammer-on" design

Securely holds conductors, reducing maintenance and improving wayside safety

Quick and easy hammer-on installation

Fits various rail profiles

Does not require removal of the ballast material

Multi-layer proprietary coating provides optimal corrosion protection

SPECIFICATIONS

Rail Type: 40 kg to 65 kg T-Rail Sections


Material: Spring Steel

Table 1/1

Catalog Number	Finish	Length (L)	Width (W)	Rail Foot Thickness (RFT)	Diameter (Ø)
EM58SN25CA	Multi-Layer Proprietary Coating	2.76"	1 3/4"	0.310" - 0.55"	0.980" - 1.1"

Catalog Number	Finish	Length (L)	Width (W)	Rail Foot Thickness (RFT)	Diameter (Ø)
EM58SN39SH	Multi-Layer Proprietary Coating, Cataphoresis and Polyester Black Treatment	3.15"	1 3/4"	0.310" - 0.55"	0.710" - 0.79"
EM58SN3SH	Multi-Layer Proprietary Coating, Cataphoresis and Polyester Black Treatment	2.76"	1 3/4"	0.310" - 0.55"	0.980" - 1.1"
EM58SN4SH	Multi-Layer Proprietary Coating, Cataphoresis and Polyester Black Treatment	2.56"	1 3/4"	0.310" - 0.55"	0.530" - 0.61"
EM58SN5SH	Multi-Layer Proprietary Coating, Cataphoresis and Polyester Black Treatment	2.76"	1 3/4"	0.310" - 0.55"	0.810" - 0.93"

DIAGRAMS

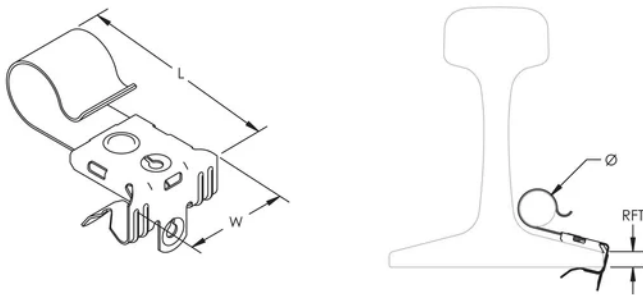

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE