

Stamped Bolted Parallel Cable Connector



CERTIFICATIONS



FEATURES

For positive bolt tension cable clamping

Listed to UL® 96

SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/1


Catalog Number	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA502	Aluminum		1 1/2"	1 1/2"	1.78"	0.09 lb
LPC502L	Copper	Tinned	1 1/2"	1 1/2"	1.78"	0.21 lb
LPC502A	Copper, Aluminum, Stainless Steel 304 (EN 1.4301)		1 1/2"	1 1/2"	1.78"	0.19 lb

CatalogNumber	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPC502	Copper		1 1/2"	1 1/2"	1.78"	0.21 lb

ADDITIONAL PRODUCT DETAILS

Stainless steel separator included with LPC502A for bi-metallic applications.

DIAGRAMS

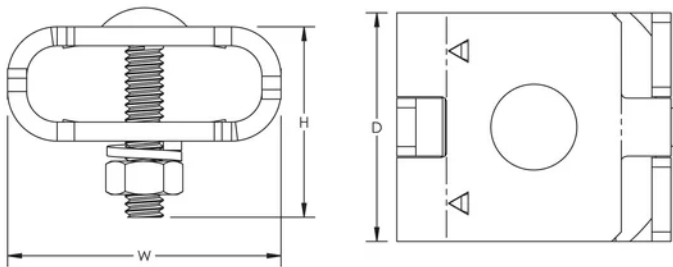

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE