

Surge Diverter, 100 kA Single Mode



CERTIFICATIONS



FEATURES

100 kA 8/20 μ s maximum surge rating provides protection suitable for smaller main-distribution panels and an extended operational life


Indication flag provides clear visual indication of life status

SPECIFICATIONS

Catalog Number	DSD11001S275
Nominal System Voltage (Un)	220 - 240 V
Max Continuous Operating Voltage (Uc)	275 VAC 350 VDC
Max Discharge Current (Imax)	100kA 8/20 μ s
Nominal Discharge Current (In)	40kA 8/20 μ s
Voltage Protection Level (Up)	850 V @ 3 kA 1600 V @ 40 kA
Voltage Protection Level (Up) @ In	1600V
Impulse Current (Iimp)	12kA 10/350 μ s

Catalog Number	DSD11001S275
Distribution System	TN-C TN-C-S TN-S TT
Frequency	0 - 60 Hz
Protection Modes	Single
Short Circuit Current Rating (SCCR)	25kA
Technology	MOV with thermal disconnect
Connection, Solid	35 mm ² Max
Connection, Solid	#2 max
Connection, Stranded	#4 max
Mounting	35 mm top hat DIN rail
Enclosure Material	UL® 94V-0 Thermoplastic
Enclosure Rating	IP 20 NEMA®-1
Remote Contacts	No
Status Indication	Mechanical flag
Terminal Torque	31 in·lb Max
Module Width	1 M
Temperature	-40 to 176 °F
Depth (D)	2.68"
Height (H)	3.54"
Width (W)	0.71"
Unit Weight	0.3 lb
Complies With	ANSI®/IEEE® C62.41.2-2002 Cat A, Cat B, Cat C ANSI®/IEEE® C62.41.2-2002 Scenario II, Exposure 3, 100 kA 8/20 µs, 10 kA 10/350 µs IEC® 61643-1 Class I, Class II

DIAGRAMS

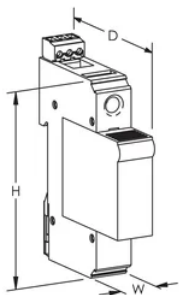

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE