


# Through Roof PVC Assembly, Parallel Conductor to In-Line Conductor



## CERTIFICATIONS

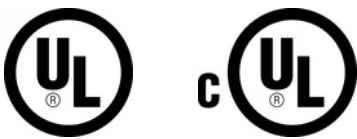

## FEATURES

Allows for lightning protection conductors to be concealed in ceiling or walls

Use in-line connection for conductor and secure to structure using base plate

## SPECIFICATIONS

**Conductor Size, UL:** Class 1 - Class 2 (4/0 Max)

Table 1/2

Catalog Number	Material	Connection Material, In-Line Conductor	Connection Material, Parallel Conductor	Rod Length (L)	Rod Size (RS)
LPC66518	Copper, Polyvinylchloride, Stainless Steel 18-8 (EN 1.4305)	Copper	Copper	20"	1/2"

Catalog Number	Material	Connection Material, In-Line Conductor	Connection Material, Parallel Conductor	Rod Length (L)	Rod Size (RS)
LPC66518BI	Aluminum, Copper, Polyvinylchloride, Stainless Steel 18-8 (EN 1.4305)	Copper	Bi-Metallic	20"	1/2"
LPC66524	Copper, Polyvinylchloride, Stainless Steel 18-8 (EN 1.4305)	Copper	Copper	26"	1/2"
LPC66524BI	Aluminum, Copper, Polyvinylchloride, Stainless Steel 18-8 (EN 1.4305)	Copper	Bi-Metallic	26"	1/2"


Table 2/2

Catalog Number	Outer Diameter (OD)	Unit Weight
LPC66518	1.9"	2.79 lb
LPC66518BI	1.9"	2.75 lb
LPC66524	1.9"	3.19 lb
LPC66524BI	1.9"	3.19 lb

## ADDITIONAL PRODUCT DETAILS

Always consult the roof manufacturer or owner for proper flashing materials.

DIAGRAMS

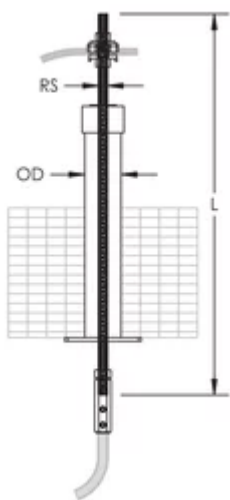

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including vinyl chloride, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE