

# ABS Adjustable Busbar Support Insulator Module



## CERTIFICATIONS



## FEATURES

Modules provide flexibility to select distance between phases and supports

Extremely robust construction

Halogen free insulators

RoHS compliant

## SPECIFICATIONS

<b>Max Working Voltage, IEC (Ui):</b>	1000;1500
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel;Glass Fibre Reinforced Polyamide;Stainless Steel 304 (EN 1.4301)
<b>Complies With:</b>	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
<b>Flammability Rating:</b>	UL® 94V-0
<b>Working Temperature:</b>	-40 to 266 °F

Table 1/2

Catalog Number	Article Number	Typical Application Current Rating	Busbars per Phase	Busbar Thickness	Busbar Width	Width (W)
ABS1-5MOD	560860	1700 A Max	1	0.2"	1.970" - 4.92"	2.91"
ABS4-5MOD	560870	3500 A Max	1 - 4	0.2"	1.970" - 4.92"	3.9"
ABS1-10MOD	560880	2250 A Max	1	0.39"	1.970" - 4.92"	2.91"
ABS2-10MOD	560890	3600 A Max	1 - 2	0.39"	1.970" - 4.92"	3.9"
ABS3-10MOD	560900	4500 A Max	1 - 3	0.39"	1.970" - 4.92"	4.88"


Table 2/2

Catalog Number	Article Number	Depth (D)	Unit Weight
ABS1-5MOD	560860	2.64"	1.41 lb
ABS4-5MOD	560870	2.64"	1.61 lb
ABS1-10MOD	560880	2.64"	1.41 lb
ABS2-10MOD	560890	2.64"	1.61 lb
ABS3-10MOD	560900	2.64"	1.79 lb

## ADDITIONAL PRODUCT DETAILS

ABS Adjustable Busbar Support High Ampacity Kit available to support up to 200 mm (7.87") busbar width for applications up to 7400 A.

DIAGRAMS

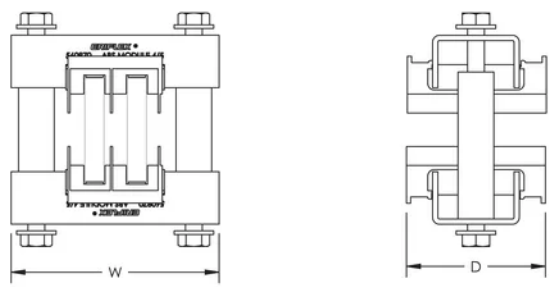

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE