

BC Ribbed Steel Busbar Clamp



CERTIFICATIONS



FEATURES

Connects two copper busbars together or nVent ERIFLEX Flexibar to copper busbar

Two ribbed plates complete with screws

Allows for excellent electrical contact

Installs quickly and easily

Ideal for on site modifications

RoHS compliant

SPECIFICATIONS

Clamping Capacity: 0.79"

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	Busbar Width	Width (W)	A	Screw Diameter (Sc)	Torque (TQ)
BC80	553250	3.15"	4.65"	3.78"	10	40 ft·lbf

CatalogNumber	Article Number	Busbar Width	Width (W)	A	ScrewDiameter (Sc)	Torque (TQ)
BC30	553200	1.18"	2.2"	1.65"	6	5.16 ft·lbf
BC40	553210	1.57"	2.6"	2.05"	6	5.16 ft·lbf
BC50	553220	1.97"	3.27"	2.52"	8	14.75 ft·lbf
BC63	553230	2.48"	3.66"	2.91"	8	14.75 ft·lbf
BC100	553260	3.94"	5.67"	4.65"	10	40 ft·lbf

Table 2/2		
Catalog Number	Article Number	Unit Weight
BC80	553250	2.6 lb
BC30	553200	0.68 lb
BC40	553210	0.81 lb
BC50	553220	1.3 lb
BC63	553230	1.63 lb
BC100	553260	3.79 lb

DIAGRAMS

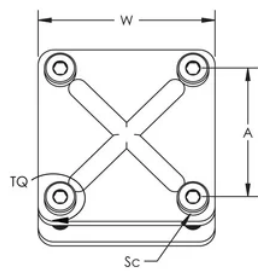

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE