

CAPN Cap Nut



CERTIFICATIONS



FEATURES

For use with DH Distance Holder and Spacer

SPECIFICATIONS

Flammability Rating: UL® 94HB

Temperature: 176 °F Max


Table 1/2

Catalog Number	Article Number	Material	Thread Size (TS)	Thread Depth (TD)	Height (H)	Width (W)
CAP-CAPN15	560820	Polystyrene, Brass	M5	0.31"	0.47"	0.55"
CAP-CAPN16	560830	Polystyrene, Brass	M6	0.31"	0.47"	0.55"
CAP-CAPN5	560800	Polystyrene	M5	0.31"	0.47"	0.55"
CAP-CAPN6	560810	Polystyrene	M6	0.31"	0.47"	0.55"

Table 2/2

Catalog Number	Article Number	Unit Weight
CAP-CAPN15	560820	0.01 lb
CAP-CAPN16	560830	0.01 lb
CAP-CAPN5	560800	0 lb
CAP-CAPN6	560810	0 lb

DIAGRAMS

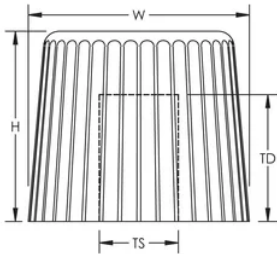

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE