


EB-130 Earthing and Neutral Busbar

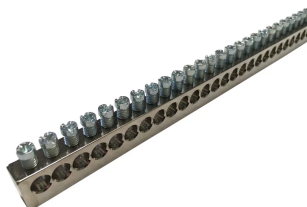

CERTIFICATIONS



FEATURES

- Use to connect several earthing conductors
- Chamfered holes allow for easy connections
- Main terminal clamp available for thicker conductors
- Support bracket available for attaching busbar to DIN rail
- Nickel plating is corrosion resistant
- Rigid bar
- Cut to length as needed
- Quick and easy installation
- RoHS compliant

SPECIFICATIONS

Catalog Number	EB130
Article Number	568673
Material	Brass

Catalog Number	EB130
Finish	Nickel Plated
Number of Connections	130
Conductor Size, IEC	1.5 - 25 mm ² Stranded
Max Current Rating	125A
Cross Section	296kcmil
Depth (D)	0.6"
Height (H)	0.4"
Width (W)	39.4"
Hole Size (HS)	0.26"
Thread Size (TS)	M5
A	0.28"
Torque (TQ)	1.48 ft·lbf
Unit Weight	2.28 lb
Complies With	IEC® 60998-2-1

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE