


EC35 Earthing/Grounding Connector

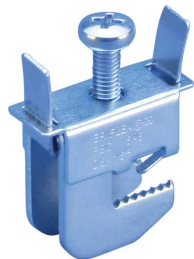

CERTIFICATIONS



FEATURES

Very compact clamp for connecting cable conductors to earthing busbar without drilling

Conductor is clamped with a pressure plate

Clamps can be mounted and slid into position on busbar prior to connecting conductors

Connections can be added after busbar has been mounted

Single screw locks clamp and makes connection

EAC compliant

RoHS compliant

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Finish	Material	Busbar Thickness	Busbar Width	Conductor Size
EC35	553470	Electrogalvanized	Steel	0.16" - 0.2"	0.47"	2.5 mm ² Solid - 35 mm ² Stranded

Table 2/2

Catalog Number	Article Number	Depth (D)	Height (H)	Width (W)	Torque (TQ)	Unit Weight
EC35	553470	0.55"	1.06"	1.22"	4.4 ft·lbf	0.06 lb

DIAGRAMS

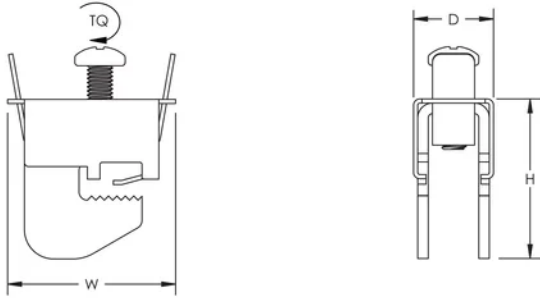

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE