


FTCB Flat Braid in Coil, Tinned Copper

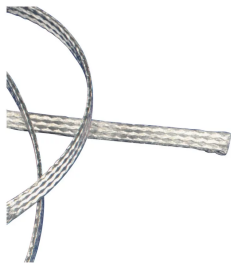

CERTIFICATIONS



FEATURES

Braids in coil are mainly used for power distribution or earthing applications

Non-magnetic material

Tinned finish provides a theft-deterrent appearance

SPECIFICATIONS

Wire Diameter: 0.01"

Material: Copper

Finish: Tinned

Table 1/2

Catalog Number	Article Number	Nominal Current	Cross Section	Number of Wires	Length	Thickness
FTCB15-10	557230	75A	19.74kcmil	576	82'	0.06"
FTCB15-100	557350	360A	197.35kcmil	5664	82'	0.16"

CatalogNumber	Article Number	Nominal Current	Cross Section	Number of Wires	Length	Thickness
FTCB15-16	557240	120A	31.57kcmil	896	82'	0.06"
FTCB15-20	557250	140A	39.47kcmil	1120	82'	0.06"
FTCB15-25	557260	150A	49.34kcmil	1404	82'	0.07"
FTCB15-3	557200	30A	5.92kcmil	168	82'	0.04"
FTCB15-30	557270	180A	59.2kcmil	1692	82'	0.08"
FTCB15-35	557280	200A	69.07kcmil	1980	82'	0.1"
FTCB15-40	557290	220A	78.94kcmil	2272	82'	0.1"
FTCB15-5	557210	45A	9.87kcmil	288	82'	0.04"
FTCB15-50	557300	250A	98.68kcmil	2848	82'	0.12"
FTCB15-60	557310	280A	118.41kcmil	3392	82'	0.12"
FTCB15-70	557320	290A	138.15kcmil	3968	82'	0.14"
FTCB15-75	557330	300A	148.01kcmil	4256	82'	0.16"
FTCB15-8	557220	65A	15.78kcmil	456	82'	0.06"
FTCB20-10	503520	75A	19.74kcmil	576	492'	0.06"
FTCB20-16	503530	120A	31.57kcmil	896	492'	0.08"
FTCB20-25	503540	150A	49.34kcmil	1404	328'	0.07"

Table 2/2

Catalog Number	Article Number	Width	Unit Weight
FTCB15-10	557230	0.4"	0.22 lb

Catalog Number	Article Number	Width	Unit Weight
FTCB15-100	557350	1.6"	2.2 lb
FTCB15-16	557240	0.6"	0.35 lb
FTCB15-20	557250	0.8"	0.44 lb
FTCB15-25	557260	0.73"	0.55 lb
FTCB15-3	557200	0.2"	0.07 lb
FTCB15-30	557270	0.9"	0.66 lb
FTCB15-35	557280	0.9"	0.77 lb
FTCB15-40	557290	1"	0.88 lb
FTCB15-5	557210	0.3"	0.11 lb
FTCB15-50	557300	1.1"	1.1 lb
FTCB15-60	557310	1.2"	1.32 lb
FTCB15-70	557320	1.2"	1.54 lb
FTCB15-75	557330	1.2"	1.65 lb
FTCB15-8	557220	0.3"	0.18 lb
FTCB20-10	503520	0.4"	0.22 lb
FTCB20-16	503530	0.6"	0.35 lb
FTCB20-25	503540	0.73"	0.55 lb

ADDITIONAL PRODUCT DETAILS

Unit weight is per meter (3.28').

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE