


RFS Reinforced nVent ERIFLEX Flexibar Support

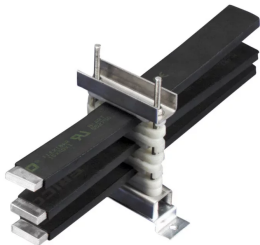

CERTIFICATIONS



FEATURES

Supports up to eight conductors in parallel

Ensures correct spacing for optimum cooling

Easy to install

Spacers are halogen free

RoHS compliant

SPECIFICATIONS

Material: Stainless Steel 304 (EN 1.4301);Polyamide

Table 1/3

Catalog Number	Article Number	Conductor Width	Depth (D)	Height (H)	Width (W)	Hole Size (HS)
RFS80-100	553380	3.15" - 3.94"	1.57"	8.26"	8.86"	0.35"
RFS40-63	553370	1.57" - 2.48"	1.57"	8.26"	6.89"	0.35"

Table 2/3

Catalog Number	Article Number	Thread Size (TS)	A	B	C	Unit Weight
RFS80-100	553380	M10	7.87"	6.69"	5.51"	3.15 lb
RFS40-63	553370	M8	5.9"	4.72"	3.54"	2.05 lb


Table 3/3

Catalog Number	Article Number	Certifications
RFS80-100	553380	RoHS
RFS40-63	553370	CE, ERIFLEX IFBS, RoHS

ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

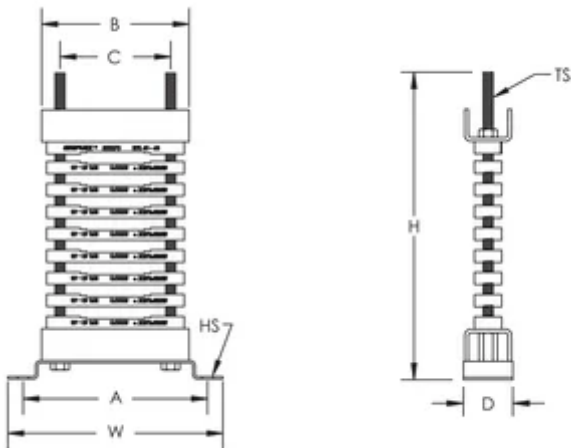

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE