


ComLine OSP Wall-Mount Rack Angles

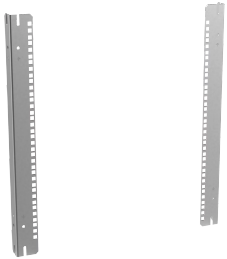

The ComLine OSP Wall-Mount Rack Angles are used to mount 19in rack equipment inside the cabinet. They are grounded to the cabinet body through the mounting bolts. Please note the square mounting holes meet EIA standard and each package includes one pair.

FEATURES

The ComLine OSP Wall-Mount Rack Angles are used to mount 19in rack equipment inside the cabinet

They are grounded to the cabinet body through the mounting bolts

Please note the square mounting holes meet EIA standard and each package includes one pair

SPECIFICATIONS

| Table 1/1 | | | | | | |
|----------------|----------------|------------|-------------|-----------|------------|------------|
| Catalog Number | Article Number | Material | Finish | Thickness | Rack Units | Rack Width |
| ERA196S | 17037 | Mild Steel | Zinc Plated | 12ga | 12U | 19in |
| ERA199S | 17038 | Mild Steel | Zinc Plated | 12ga | 18U | 19in |
| ERA19239S | 17041 | Mild Steel | Zinc Plated | 12ga | 18U | 19in, 23in |
| ERA192312S | 17042 | Mild Steel | Zinc Plated | 12ga | 25U | 19in, 23in |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE