


Elbow 90-Degree Inside Opening Lay-in Galvanized

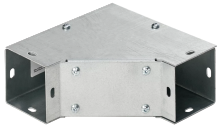

Lay-in Galvanized 90-Degree Elbow with Inside Opening are used for continuous run with 90-degree turns. Top and inside covers removable. Lay-in feature allows wires and cables can be laid in along wireway run. No pulling through of wires or cables prevents damage to insulation that often occurs in a pull-through wiring system.

FEATURES

Lay-in Galvanized 90-Degree Elbow with Inside Opening are used for continuous run with 90-degree turns

Top and inside covers removable

Lay-in feature allows wires and cables can be laid in along wireway run

No pulling through of wires or cables prevents damage to insulation that often occurs in a pull-through wiring system

SPECIFICATIONS

Finish: Galvanized
Material: Mild Steel

Table 1/1						
Catalog Number	Article Number	Type	Height	Width	Thickness	Quick Ship
F8890EINGV	13146	Elbow	8in	8in	14ga	No
F121290EINGV	13148	Elbow	12in	12in	14ga	No
F4490EINGV	13144	Elbow	4in	4in	16ga	No
F6690EINGV	13145	Elbow	6in	6in	16ga	No
F101090EINGV	13147	Elbow	10in	10in	14ga	No
F2290EINGV	13143	Elbow	2.5in	2.5in	16ga	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE