


Elbow 90-Degree Tee-Cross Lay-in Galvanized

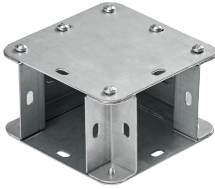

Lay-in Galvanized 90-Degree Elbow-Tee-Crosses are used for left or right 90-degree turns. Can be used as a tee or cross. Use with open adapter for cable entrance in top and bottom. Includes two closure plates.

FEATURES

Lay-in Galvanized 90-Degree Elbow-Tee-Crosses are used for left or right 90-degree turns

Can be used as a tee or cross. Use with open adapter for cable entrance in top and bottom

Includes two closure plates

SPECIFICATIONS

Finish: Galvanized
Material: Mild Steel

Table 1/1						
Catalog Number	Article Number	Type	Height	Width	Thickness	Quick Ship
F121290TXGV	88970	Elbow	12in	12in	14ga	No
F2290TXGV	87990	Elbow	2.5in	2.5in	16ga	No
F4490TXGV	88260	Elbow	4in	4in	16ga	No
F101090TXGV	45370	Elbow	10in	10in	14ga	No
F6690TXGV	88550	Elbow	6in	6in	16ga	No
F8890TXGV	88770	Elbow	8in	8in	14ga	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE