


Hygienic Design Wall Mounted Enclosure, HDW

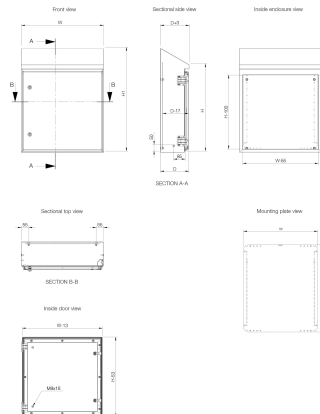

The nVent HOFFMAN Hygienic Design HDW range is designed and constructed with special materials for high sanitary operations and ease of thorough cleaning. The gapless design, the self-drainable high-polished surfaces, together with a high protection degree help reduce non operative hours, such as cleaning and maintenance, which leads to increased productivity.

INDUSTRY STANDARDS

cULus_UL

CE, UK CA, UL

IP

FEATURES

Material: Body: 1.5 mm. Door: 2 mm. AISI 304L pre-grained stainless steel. Mounting plate: 2 mm galvanized steel.

Body: Monoblock body, folded and seam welded. The top of the body is equipped with a sloping roof at an angle of 30° toward the front, ending with a 30 mm overhang to avoid any draining liquids from dripping onto the gasket and the door.

Door: Folded with a sloping angle of 8° on all sides. Surface mounted with 120° opening. Concealed zinc plated steel hinges with captive pin. Can be mounted to give left- or right-hand opening (machining is not required).

Internal hinge: The door hinge is specially designed to be concealed inside the enclosure once the door is closed to avoid dirt from accumulating, making the enclosure easy to clean.

Gasket: A one piece removable blue silicone gasket with molded corners ensures proper sealing, and makes removing and replacing it faster and easier for cleaning and replacement operations. The silicone is FDA 21 CFR 177.2600 compliant.

Lock: HD lock made of stainless steel AISI 316L with blue silicone gasket, the lock conforms with norm DIN EN 1672-2:2009.

Mounting plate: Fixed onto M8 studs welded on the rear of the enclosure. All sides from 800 mm and above are strengthened by folded edges. The mounting plate is marked vertically at 10 mm intervals for easy horizontal positioning of equipment.

Cable access: No gland openings as standard to avoid hygiene risks.

Protection: Corresponds with IP 66/69, TYPE 4X, 12, 13, IK08.

Finish: 400 Pre-grained stainless steel, polished to $Ra < 0.8 \mu m$.

Delivery: Enclosure with door, mounting plate, metallic key and mounting accessories.

Additional information: For accessories on the outside of the enclosure, please see our HD accessories section.

SPECIFICATIONS

- Thickness (T):

0.06in
- Degree of Slope:


30°
- Finish:

Brushed
- Material:

Stainless Steel 304

Table 1/1					
Catalog Number	Height (H)	Width (W)	Depth (D)	Panel Size	Quick Ship
HDW0442215	17.4in	8.66in	6.1in	13.78 x 6.3in	No
HDW0553921	21.73in	15.35in	8.27in	16.93 x 12.99in	No
HDW0558121	21.73in	31.89in	8.27in	16.93 x 29.53in	No
HDW0606130	23.82in	24.02in	11.81in	16.93 x 21.65in	No
HDW0675121	26.46in	20.08in	8.27in	21.65 x 17.72in	No
HDW0773921	30.39in	15.35in	8.27in	25.59 x 12.99in	No
HDW0776121	30.39in	24.02in	8.27in	25.59 x 21.65in	No
HDW0828130	32.48in	31.89in	11.81in	25.59 x 29.53in	No
HDW1228130	48.23in	31.89in	11.81in	41.34 x 29.53in	No
HDW1428130	56.1in	31.89in	11.81in	49.21 x 29.53in	No

DIAGRAMS

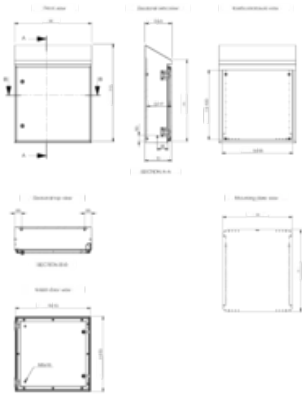

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE