


Mounting Angles (19-inch), DNN

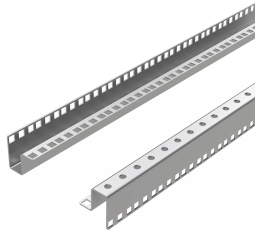

19" equipment can be easily fitted in consoles, either in the factory or in the field, when these profiles are used.

FEATURES

Description: To achieve 19" or partial 19" in 800 mm wide enclosures, these profiles can be mounted with the mounting brackets DNB. To achieve 19" in 600 mm wide enclosures, use the brackets DND.

Material: 2 mm zinc plated steel.

Pack quantity: 2 pieces.

SPECIFICATIONS

Thickness: 0.08in
Material: Steel
Finish: Zinc Plated

Table 1/1

Catalog Number	Height	Width	Depth	Rack Units	Enclosure Material	Quick Ship
DNN06	10.51in	1.77in	1.93in	6U	Mild Steel, Stainless Steel	No
DNN09	15.75in	1.77in	1.93in	9U	Mild Steel, Stainless Steel	No
DNN10	17.52in	1.77in	1.93in	10U	Mild Steel, Stainless Steel	No
DNN11	19.25in	1.77in	1.93in	11U	Mild Steel, Stainless Steel	No
DNN13	22.8in	1.77in	1.93in	13U	Mild Steel, Stainless Steel	No
DNN15	26.26in	1.77in	1.93in	15U	Mild Steel, Stainless Steel	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE