


ProLine G2 Adjustable Rack-Mounting Rails

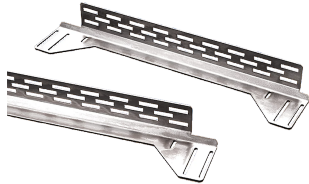

ProLine G2 Adjustable Rack-Mounting Rails allow 19-in. Rack Angles to be positioned anywhere within the modular enclosure frame.

FEATURES

Includes two right-hand and two left-hand mounting rails

12 gauge (2.5 mm) conductive steel

Mounting hardware is included

SPECIFICATIONS

Thickness: 12ga
Finish: Plated

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Material	Quick Ship
P2GARA5	31894	2.87in	3.82in	16.1in	Mild Steel	No
P2GARA9	31898				Mild Steel	No
P2GARA4	31893	2.87in	3.82in	12.17in	Mild Steel	No
P2GARA6	31895	2.87in	3.82in	20.04in	Mild Steel	No
P2GARA8	31897	2.87in	3.82in	27.91in	Mild Steel	No
P2GARA7	31896				Mild Steel	No
P2GARA10	31885	2.87in	3.82in	35.79in	Mild Steel	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE